


E12570



Adapter socket

EDOGH040ZDS0002E04 (PG9)

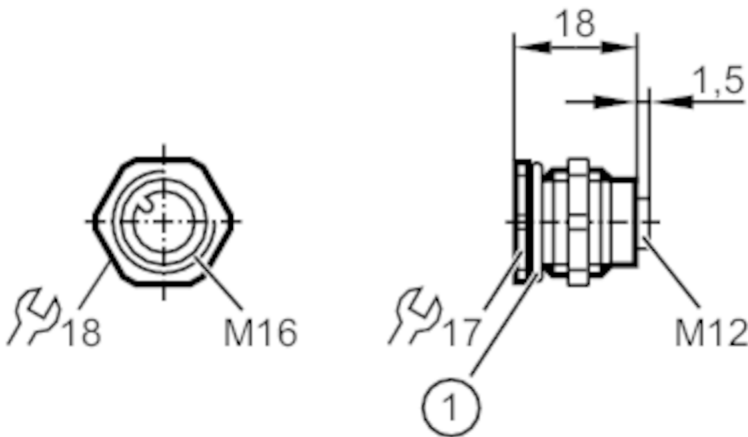

1 O-ring

Electrical data

Operating voltage	[V]	< 250 AC/DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 68

Mechanical data

Weight	[g]	38.9
Mounting thread		PG 9
Materials		diecast zinc
Moulded-body material		diecast zinc

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 2 m, PVC; 4 x 0.25 mm²

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: diecast zinc

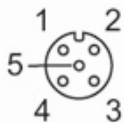

E12570



Adapter socket

EDOGH040ZDS0002E04 (PG9)

Connection



	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white