


E12582



Wirable AMP socket

SDOGV060--AFKCR

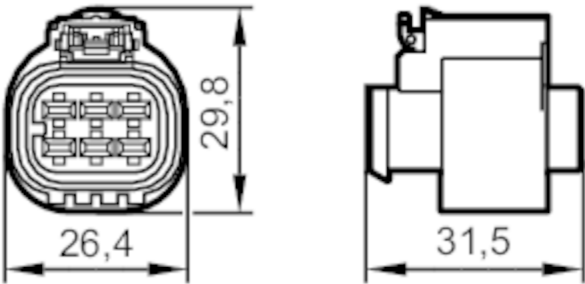

Electrical data		
Operating voltage	[V]	12...24 DC
Operating conditions		
Ambient temperature	[°C]	-40...100
Ambient temperature (moving)	[°C]	-40...100
Protection		IP 67; (mating connector plugged in)
Mechanical data		
Weight	[g]	14
Dimensions	[mm]	29.8 x 26.4 x 31.5
Materials		socket housing: PBT; Contacts: tin-plated
Аксессуары		
Items supplied		cover plug: 6
		sealing of the individual cores: 2 x 0,5 mm²
		sealing of the individual cores: 4 x 2,5 mm²
		Crimp contacts: 6
Electrical connection		
terminals: 2 x 0.5 mm²		

E12582




Wirable AMP socket

SDOGV060--AFKCR

4 x 2.5 mm²

Electrical connection - socket

Connection

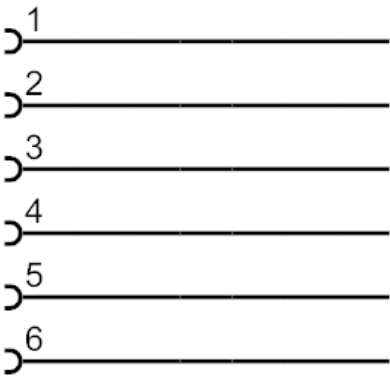

Connector: 1 x AMP connector, straight; Contacts: tin-plated