


E12613



Connection cable

ASTGH030MSS00,5H03

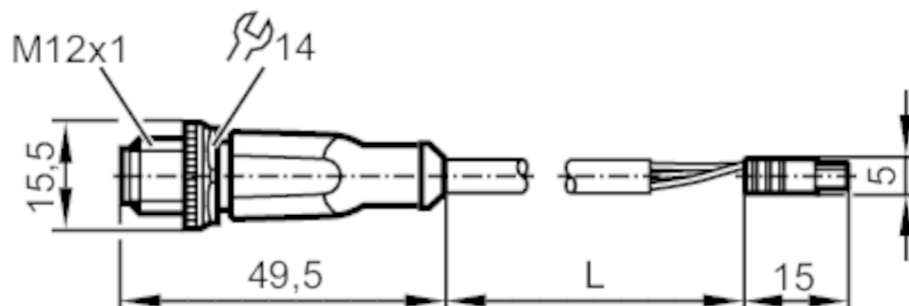

Application

Special feature	Free from silicone; Halogen-free
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 50 AC/DC
Protection class		II
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...90
Ambient temperature (moving)	[°C]	-25...90
Protection		IP 65

Mechanical data

Weight	[g]	30.5
Materials		housing: TPU orange; Lock nut: nickel-plated brass
Tightening torque	[Nm]	0.6...1.5

Remarks

Pack quantity		1 pcs.
---------------	--	--------

 
E12613



Connection cable

ASTGH030MSS00,5H03


Electrical connection



Electrical connection

Cable: 0.5 m, PUR, Halogen-free, black, Ø 4.9 mm; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Connection

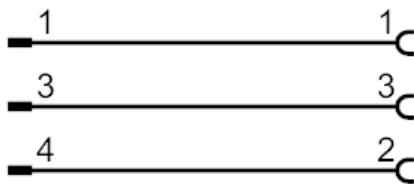

Electrical connection



1 2 3