


# E12666



## Connection cable

VDOAX050MSS00,5H05STAH005MSS

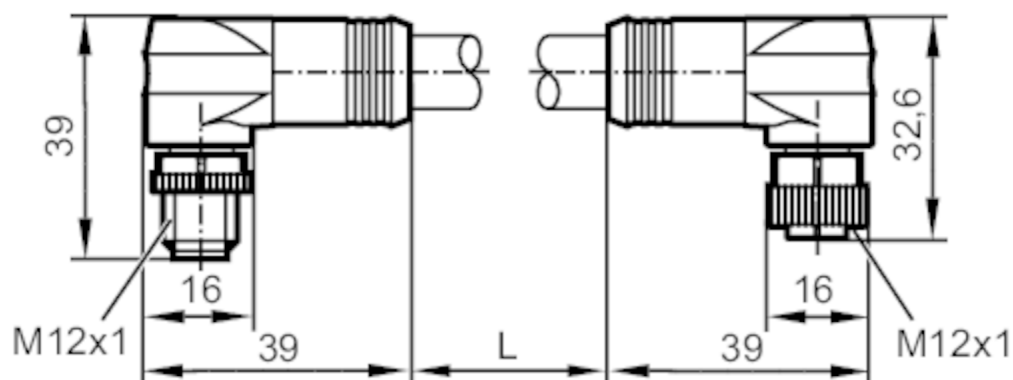

### Application

|                 |                      |
|-----------------|----------------------|
| Special feature | Gold-plated contacts |
| Design          | power cable, L-coded |

### Electrical data

|                         |     |       |
|-------------------------|-----|-------|
| Operating voltage       | [V] | 64 DC |
| Max. current load total | [A] | 16    |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -40...90 |
| Protection          |      | IP 67    |

### Mechanical data

|                       |     |                      |
|-----------------------|-----|----------------------|
| Weight                | [g] | 135.6                |
| Materials             |     | PP                   |
| Moulded-body material |     | TPE                  |
| Material nut          |     | brass, nickel-plated |

### Remarks

|               |  |        |
|---------------|--|--------|
| Pack quantity |  | 1 pcs. |
|---------------|--|--------|

# E12666



## Connection cable

VDOAX050MSS00,5H05STAH005MSS

### Electrical connection

Cable: 0.5 m, PUR, black, Ø 11.3 mm; 5 x 2.5 mm<sup>2</sup>


### Electrical connection - plug

Connector: 1 x M12, angled; coding: L; Moulded body: TPE; Locking: brass, nickel-plated; Contacts: gold-plated



### Electrical connection - 2

#### Connection

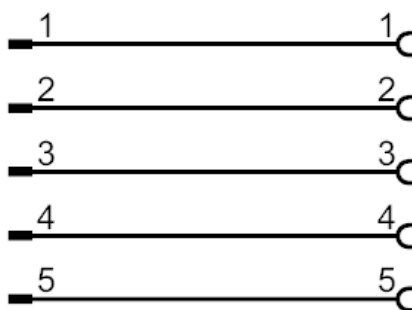

### Electrical connection - socket

Connector: 1 x M12, angled; coding: L; Moulded body: TPE; Locking: brass, nickel-plated; Contacts: gold-plated

