


E12673



Wirable plug

SSTGX050ZDSFKPG

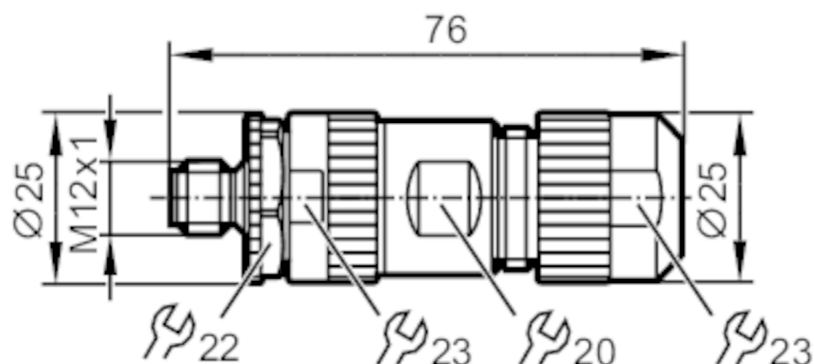

Application

Special feature	Gold-plated contacts
Design	L-coded

Electrical data

Operating voltage	[V]	< 63 DC
Max. current load total	[A]	16

Operating conditions

Ambient temperature	[°C]	-40...85
Protection		IP 67

Mechanical data

Weight	[g]	43.05
Dimensions	[mm]	Ø 25 / L = 76
Materials		PA
Moulded-body material		PA
Material nut		diecast zinc, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E12673



Wirable plug

SSTGX050ZDSFKPG

Electrical connection

screw terminals: 1.5...2.5 mm²; Cable sheath: Ø 8...13 mm

Electrical connection - plug

Connector: 1 x M12, straight; coding: L; Moulded body: PA; Locking: diecast zinc, nickel-plated; Contacts: gold-plated



Connection

