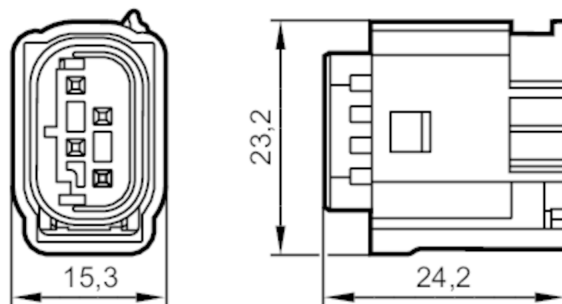


Wirable socket

ecomatPanel/Connection Set


Electrical data

Operating voltage	[V]	8...32 DC
Protection class		III
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-40...80
Protection		IP 20; (without resistor)

Mechanical data

Weight	[g]	10
Dimensions	[mm]	15.3 x 23.2 x 24.2
Materials		housing: PBT-GF20
Moulded-body material		PBT

Аксессуары

Items supplied	120 Ohm resistor
	Crimp contacts
	protective tube

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection
5 x 0.5...0.75 mm²

Connector: AMP MQS, straight; Moulded body: PBT; Contacts: tin-plated



E12737



Wirable socket

ecomatPanel/Connection Set

Connection

