


E12772



Connecting cable with socket

ADOGB050ZDS0002B05

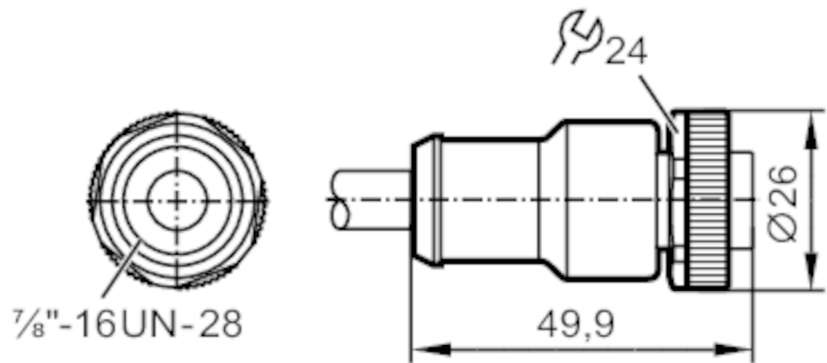

Application		
Special feature	Gold-plated contacts; Drag chain suitability	
Electrical data		
Operating voltage	[V]	< 400 AC/DC
Protection class		II
Max. current load total	[A]	5
Operating conditions		
Ambient temperature	[°C]	-25...80
Protection		IP 68
Mechanical data		
Weight	[g]	187.7
Dimensions	[mm]	26 x 26 x 49.9
Moulded-body material		PUR
Material nut		diecast zinc
Drag chain suitability		yes
Drag chain suitability	bending radius for flexible use	min. 7.5 x cable diameter
	travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s²
	bending cycles	> 5 Mio.
Remarks		
Pack quantity	1 pcs.	

E12772



Connecting cable with socket

ADOGB050ZDS0002B05

Electrical connection

Cable: 2 m, PUR, black, Ø 7.3 mm; 5 x 0.75 mm²

Electrical connection - socket

Connector: 1 x 7/8", straight; Moulded body: PUR; Locking: diecast zinc; Contacts: gold-plated



Connection

1	BK
2	BU
3	YE/GN
4	BN
5	WH