


E12774



Wirable socket  
SDOGB050ZDSFKPG

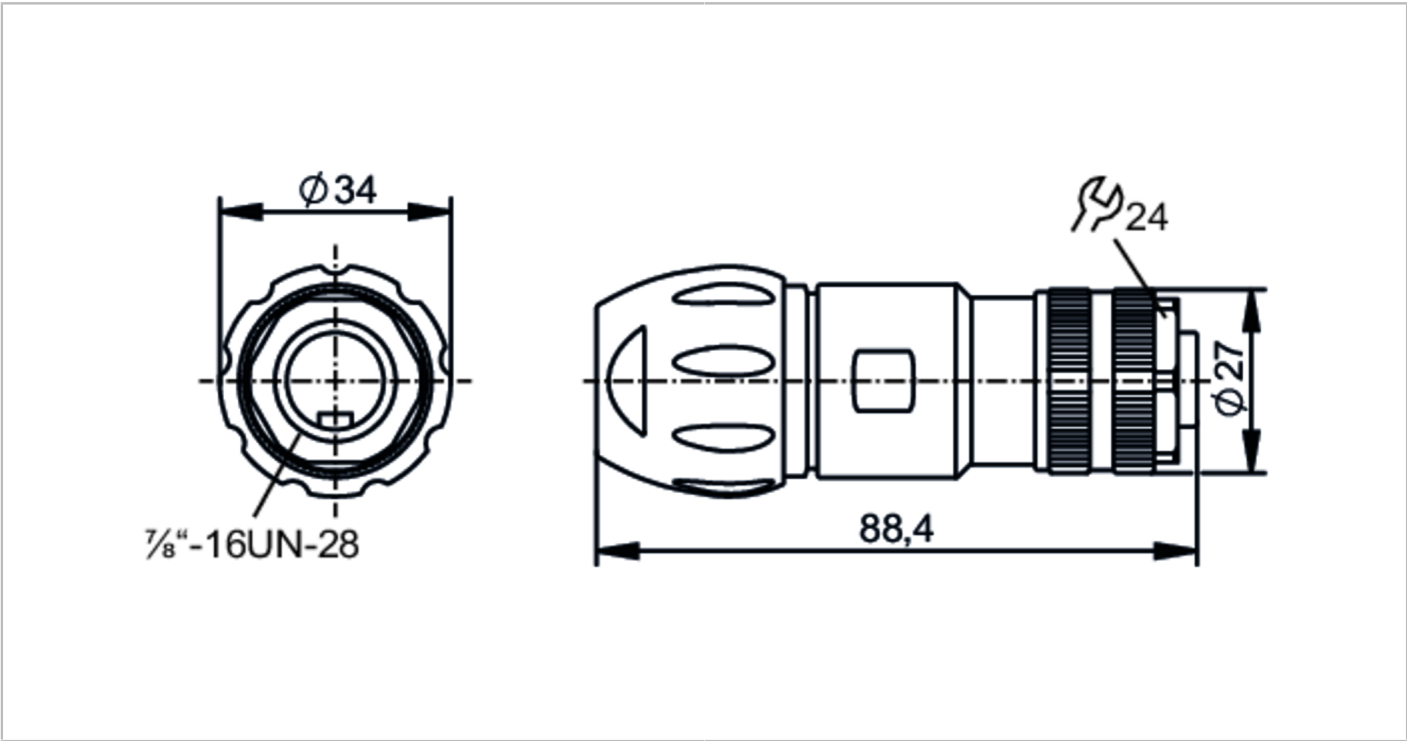

| Application             |                                          |                             |
|-------------------------|------------------------------------------|-----------------------------|
| Special feature         | Free from silicone; Gold-plated contacts |                             |
| Free from silicone      | yes                                      |                             |
| Electrical data         |                                          |                             |
| Operating voltage       | [V]                                      | < 400 AC/DC                 |
| Protection class        |                                          | II                          |
| Max. current load total | [A]                                      | 9                           |
| Operating conditions    |                                          |                             |
| Ambient temperature     | [°C]                                     | -25...85                    |
| Protection              |                                          | IP 67                       |
| Mechanical data         |                                          |                             |
| Weight                  | [g]                                      | 48.808                      |
| Moulded-body material   |                                          | PA; PUR                     |
| Material nut            |                                          | diecast zinc, nickel-plated |
| Sealing material        |                                          | NBR                         |
| Remarks                 |                                          |                             |
| Pack quantity           | 1 pcs.                                   |                             |

# E12774



## Wirable socket

SDOGB050ZDSFKPG

### Electrical connection

screw terminals: ...1.5 mm<sup>2</sup>; Cable sheath: Ø 7...13 mm; AWG 16

### Electrical connection - socket

Connector: 1 x 7/8", straight; Moulded body: PA; PUR; Locking: diecast zinc, nickel-plated; Sealing: NBR; Contacts: gold-plated



### Connection

