


E12063



Jumper cable with valve plug

STGH050MSS0006B03VDAA041--S

Article no longer available - archive entry

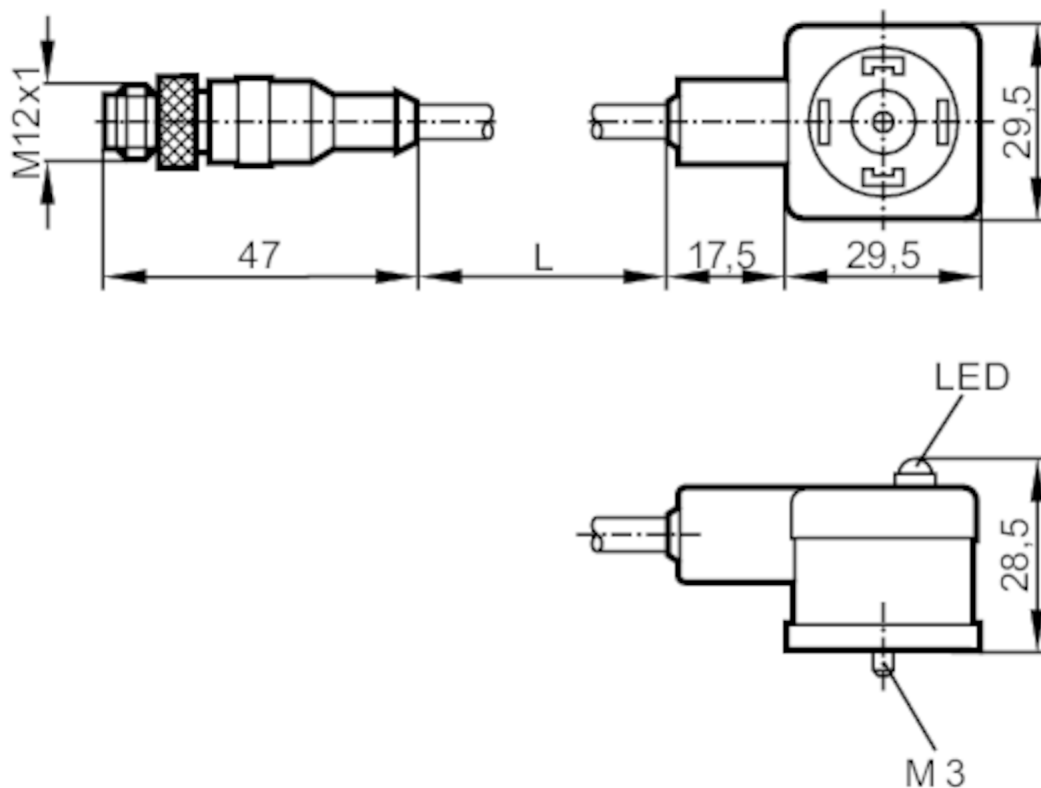

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 24 AC/DC
Overvoltage protection		free-wheeling diode

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	44
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated

Displays / operating elements

Display	operation	1 x LED, green
---------	-----------	----------------

Аксессуары

Items supplied	screw
	panel for labelling

E12063



Jumper cable with valve plug

STGH050MSS0006B03VDAA041--S

Remarks

Pack quantity

1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Contacts: gold-plated



Electrical connection

Cable: 6 m, PUR / PVC, Halogen-free; 3 x 0.5 mm² (42 x Ø 0.1 mm)

Connection



Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU; Locking: brass, nickel-plated; Contacts: nickel-plated brass

