


Y-jumper with valve plug

YVDAA042--S0003A03STGH050MSS

phase-out article

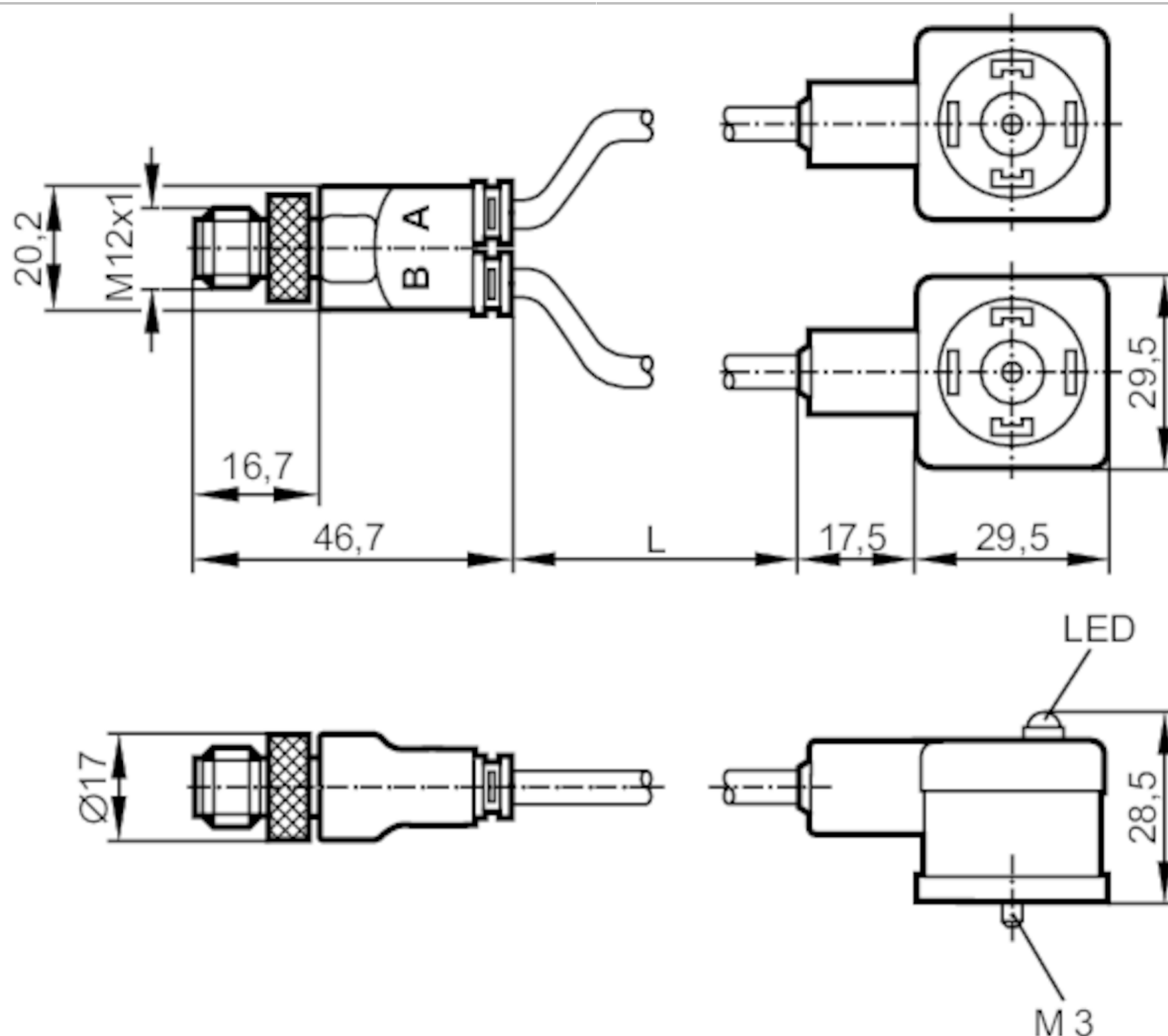

Application

Special feature

Halogen-free

Electrical data

Operating voltage [V]

10...30 DC

Overvoltage protection

yes; (VDR)

Operating conditions

Ambient temperature [°C]

-25...90

Protection

IP 65

Mechanical data

Weight [g]

350.2

Materials

TPU

Moulded-body material

TPU

Material nut

brass, nickel-plated

E12068



Y-jumper with valve plug

YVDAA042--S0003A03STGH050MSS

Displays / operating elements

Display	switching status	2 x LED, yellow
---------	------------------	-----------------

Аксессуары


Items supplied	screw
	panel for labelling

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connection

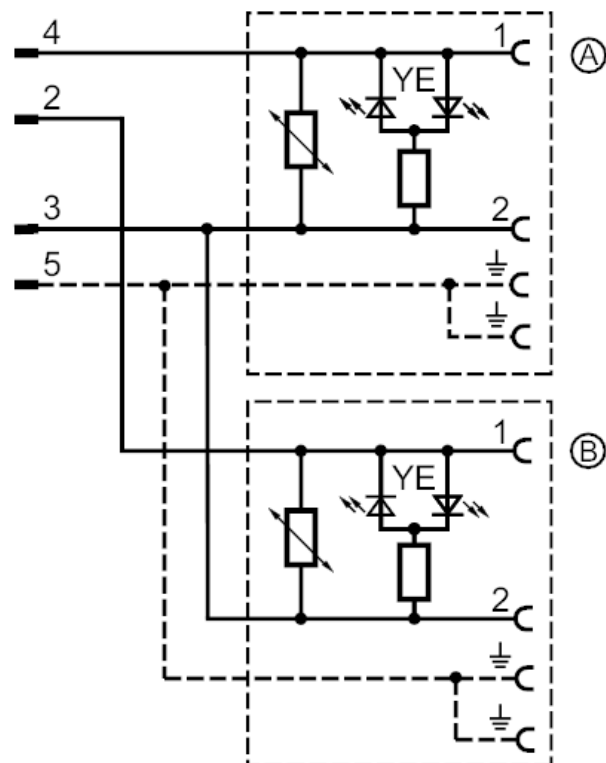

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

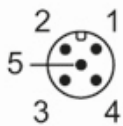

E12068



Y-jumper with valve plug

YVDAA042--S0003A03STGH050MSS

Electrical connection

Cable: 3 m, PUR, Halogen-free, black, Ø 4.8 mm; 3 x 0.5 mm² (16 x Ø 0.2 mm)

Electrical connection - socket

Connector: 2 x valve type A DIN, angled; Moulded body: TPU; Locking: brass, nickel-plated

