


Connecting cable with socket

ADOGH050MSS0010K05

Article no longer available - archive entry

Alternative articles: EVC546

When selecting an alternative article and accessories please note that technical data may differ!

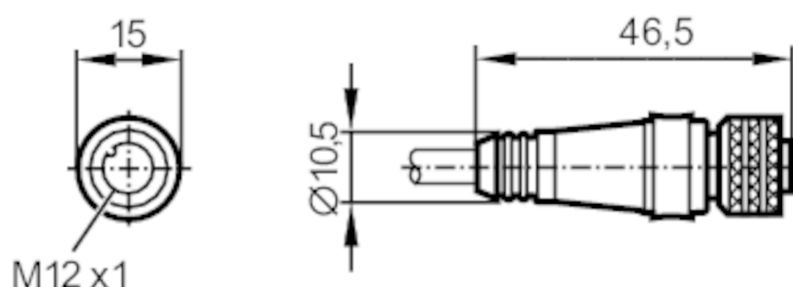

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts; Screened cable; Drag chain suitability
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Protection class		III
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	439.4
Dimensions	[mm]	15 x 15 x 46.5
Materials		PUR
Moulded-body material		PUR
Material nut		brass, nickel-plated
Drag chain suitability		yes
Drag chain suitability	bending radius for flexible use	min. 15 x cable diameter
	bending radius for fixed installation	min. 8 x cable diameter once only

E12074



Connecting cable with socket

ADOGH050MSS0010K05

Remarks


Pack quantity 1 pcs.

Electrical connection


Cable: 10 m, PUR, Halogen-free, black, Ø 5 mm, shielded; 5 x 0.25 mm² (14 x Ø 0.15 mm)

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 1.0...1.5 Nm; Shielded connection cable: screen connected

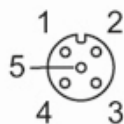

Connection

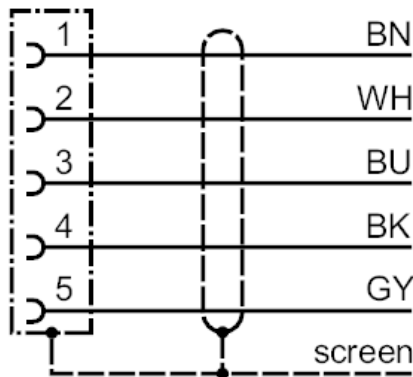

	Core colours :
BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white