


E12204



Ethernet connection cable

VSTGN040ZDS0010L04STGP040--S

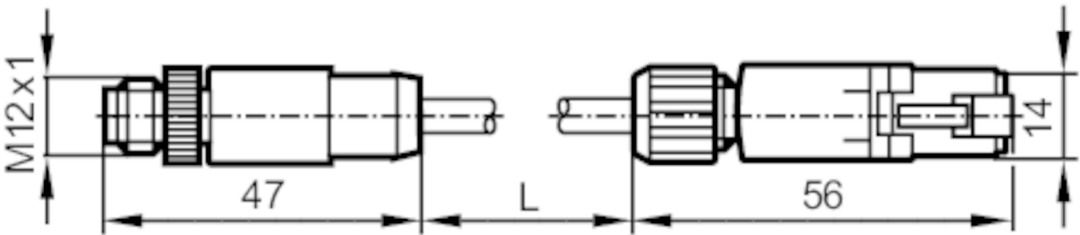

Application		
Special feature		Screened cable
Design		Ethernet cable, D-coded
Application		cross-over patch cable; patch cable
Operating conditions		
Ambient temperature	[°C]	-25...70
Protection		IP 67; IP 42; (M12 plug / RJ45 plug)
Mechanical data		
Weight	[g]	698.5
Materials		PUR / PC
Moulded-body material		PUR / PC
Material nut		diecast zinc, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection - plug M12

Connector: 1 x M12, straight; coding: D; Moulded body: PUR; Locking: diecast zinc, nickel-plated; Tightening torque: 0.7...0.9 Nm



E12204




Ethernet connection cable

VSTGN040ZDS0010L04STGP040--S

Electrical connection

Cable: 10 m, PVC, green, Ø 6.2 mm, shielded; 4 x 0.38 mm²

Connection

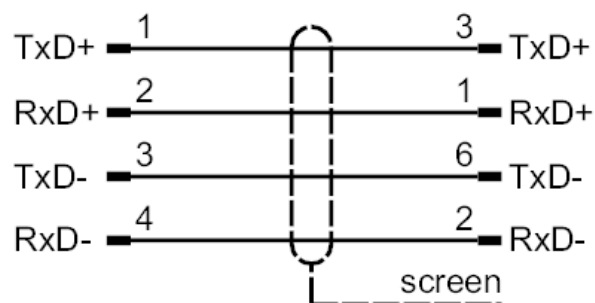

Electrical connection - plug RJ45

Connector: 1 x RJ45, straight; Moulded body: PC; Shielded connection cable: shielded

