




Ethernet connection cable

VSTAN040ZDS0002L04STGP040--S

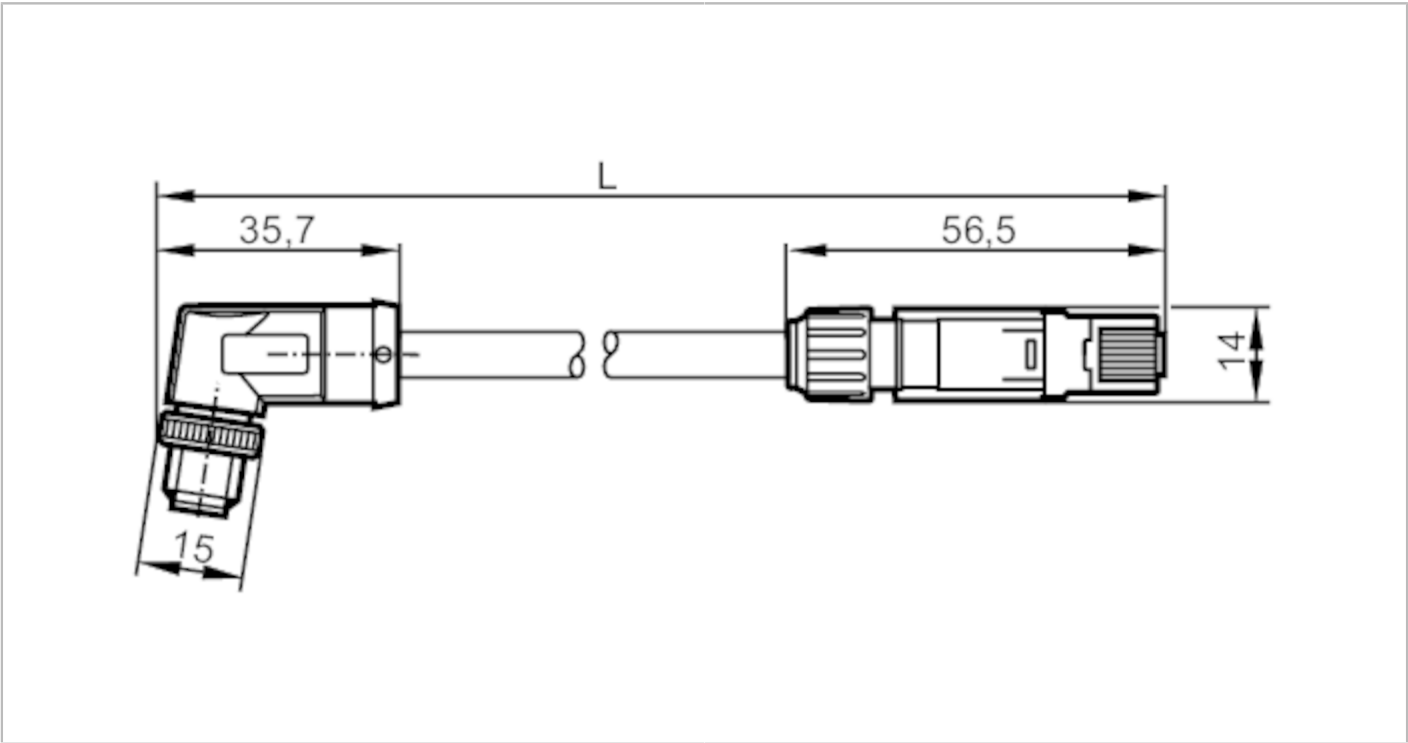

Application		
Special feature		Gold-plated contacts; Screened cable
Design		Ethernet cable, D-coded
Application		cross-over patch cable; patch cable
Operating conditions		
Ambient temperature	[°C]	-25...70
Protection		IP 67; IP 42; (M12 plug / RJ45 plug)
Mechanical data		
Weight	[g]	167.2
Materials		PUR / PC
Moulded-body material		PUR / PC
Material nut		diecast zinc, nickel-plated
Remarks		
Pack quantity		1 pcs.

E12226



Ethernet connection cable

VSTAN040ZDS0002L04STGP040--S

Electrical connection - plug M12


Connector: 1 x M12, angled; coding: D; Moulded body: PUR; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



Electrical connection

Cable: 2 m, PVC, green, Ø 6.2 mm, shielded; 4 x 0.38 mm²

Connection

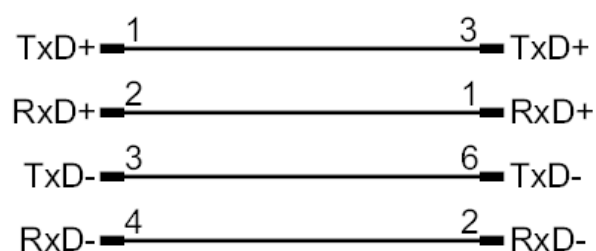

Electrical connection - plug RJ45

Connector: 1 x RJ45, straight; Moulded body: PC

