


Connecting cable with socket

ADOAH040VAS0020G04

Article no longer available - archive entry

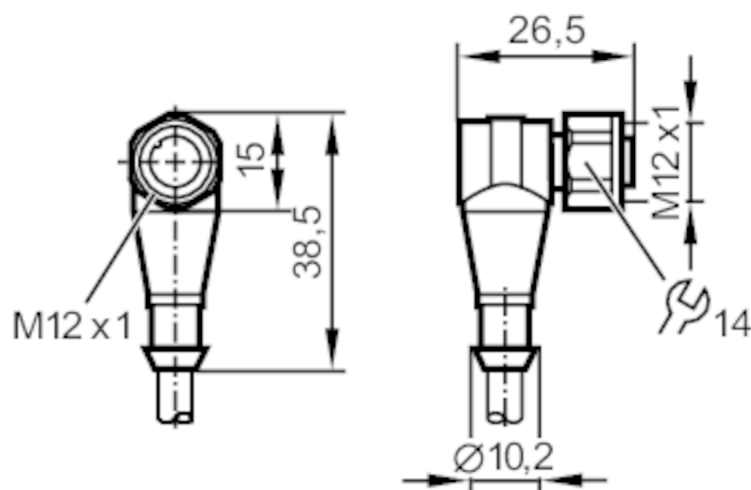

Application

Special feature	Free from silicone; Gold-plated contacts; Screened cable
Free from silicone	yes

Electrical data

Operating voltage [V]	< 50 AC / < 60 DC
Protection class	III
Max. current load total [A]	4

Operating conditions

Ambient temperature [°C]	-25...100
Protection	IP 67

Mechanical data

Weight [g]	1046.6
Dimensions [mm]	26.5 x 15 x 38.5
Materials	PVC
Moulded-body material	PVC
Material nut	stainless steel (1.4404 / 316L)

Remarks

Pack quantity	1 pcs.
---------------	--------

E12229



Connecting cable with socket


ADOAH040VAS0020G04

Electrical connection


Cable: 20 m, PVC, orange, Ø 5.3 mm, shielded; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm; Shielded connection cable: screen not connected

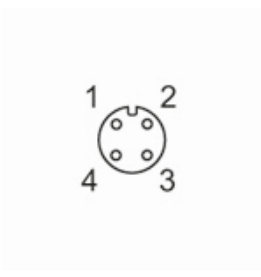

Connection

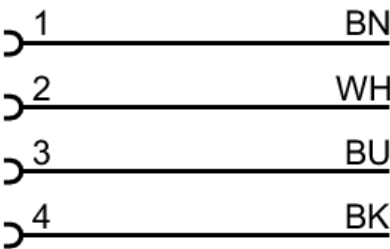

Core colours :
BK = black
BN = brown
BU = blue
WH = white