


Connecting cable with socket

ADOAA030MSS0002H03

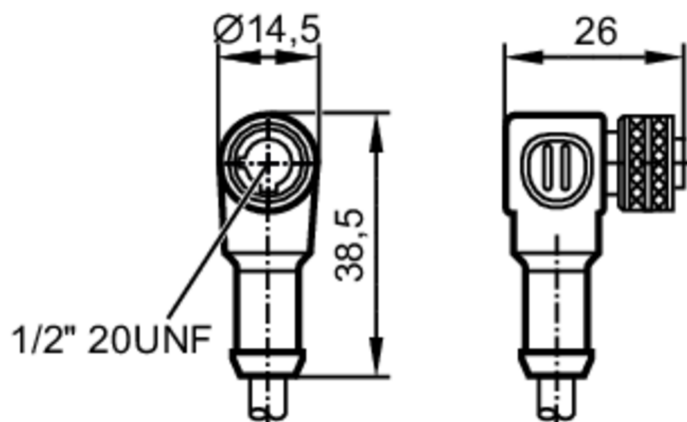

Application

Special feature	Halogen-free; Drag chain suitability
-----------------	--------------------------------------

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
-------------------	-----	---------------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	89.8
Dimensions	[mm]	26 x 14.5 x 38.5
Materials		TPU black
Moulded-body material		TPU
Material nut		brass, nickel-plated
Drag chain suitability		yes
Drag chain suitability	bending radius for flexible use	min. 10 x cable diameter
	travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s ²
	bending cycles	> 2 Mio.
	torsional strain	± 180 °/m

Remarks

Pack quantity	1 pcs.
---------------	--------

E12282



Connecting cable with socket

ADOAA030MSS0002H03

Electrical connection


Cable: 2 m, PUR, Halogen-free, black, Ø 4.8 mm; 3 x 0.5 mm² (16 x Ø 0.2 mm)

Electrical connection - socket

Connector: 1 x 1/2", angled; coding: C; Moulded body: TPU; Locking: brass, nickel-plated



Connection

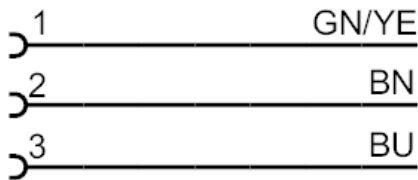

BN = Core colours : brown
BU = blue
GN/YE = green/yellow