


# E12334



## Connecting cable with socket

ADOAH040MSS0015C04

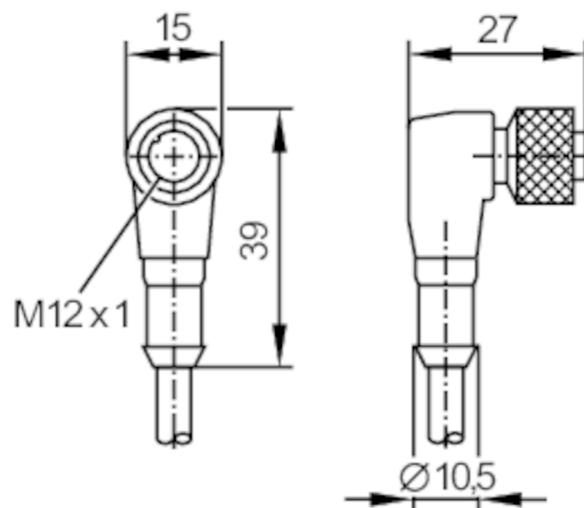

### Application

|                    |                                                                        |
|--------------------|------------------------------------------------------------------------|
| Special feature    | Free from silicone; Halogen-free; Gold-plated contacts; Screened cable |
| Free from silicone | yes                                                                    |

### Electrical data

|                         |     |                   |
|-------------------------|-----|-------------------|
| Operating voltage       | [V] | < 50 AC / < 60 DC |
| Protection class        |     | III               |
| Max. current load total | [A] | 4                 |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
| Protection          |      | IP 67    |

### Mechanical data

|                       |      |                      |
|-----------------------|------|----------------------|
| Weight                | [g]  | 0.001                |
| Dimensions            | [mm] | 27 x 15 x 39         |
| Materials             |      | TPU                  |
| Moulded-body material |      | TPU                  |
| Material nut          |      | brass, nickel-plated |

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

# E12334



## Connecting cable with socket

ADOAH040MSS0015C04

### Electrical connection


Cable: 15 m, PUR, Halogen-free, black, Ø 5 mm, shielded; 4 x 0.34 mm<sup>2</sup>

### Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm; Shielded connection cable: screen connected



### Connection

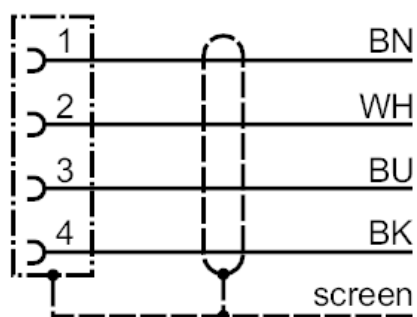

|      |                |
|------|----------------|
| BK = | Core colours : |
| BN = | black          |
| BU = | brown          |
| WH = | blue           |
|      | white          |