


Connection cable

VDOGH040MSS0,75H04STGX040--S

Article no longer available - archive entry

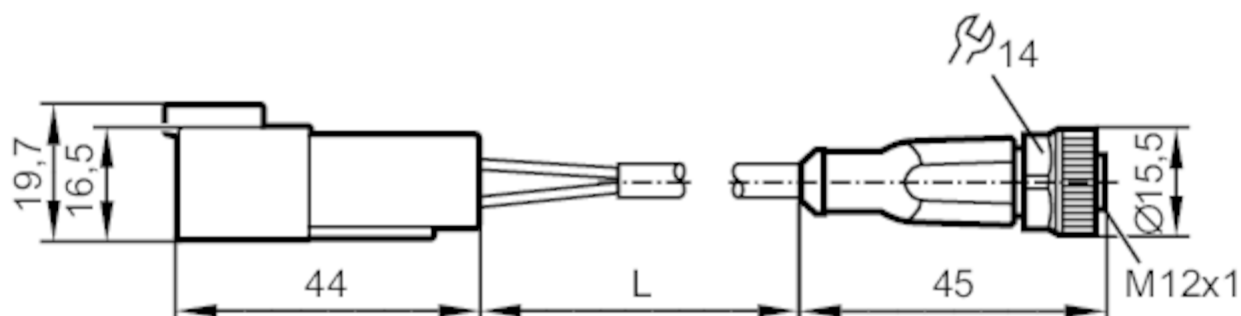

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts; Drag chain suitability
Free from silicone	yes

Electrical data

Operating voltage	[V]	10...36 DC
Protection class		II
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	54.6
Materials	socket housing: TPU orange; Sealing: FKM	
Material nut	brass, nickel-plated	
Drag chain suitability	yes	
Drag chain suitability	bending radius for flexible use	min. 10 x cable diameter
	travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s ²
	bending cycles	> 5 Mio.
	torsional strain	± 180 °/m

Remarks

Pack quantity	1 pcs.
---------------	--------

E12345



Connection cable

VDOGH040MSS0,75H04STGX040--S

Electrical connection - plug


Connector: 1 x DEUTSCH connector, straight; Contacts: nickel-plated



Electrical connection

Cable: 0.75 m, PUR, Halogen-free, black, Ø 5.1 mm; 4 x 0.50 mm² (64 x Ø 0.1 mm)

Connection

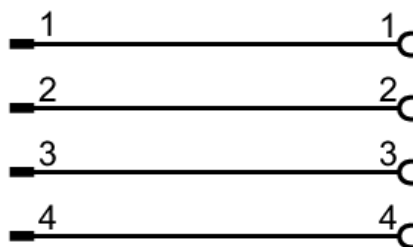

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

