


## Connecting cable with socket

ADOAH050MSS0005K05

Article no longer available - archive entry

Alternative articles: EVC548

When selecting an alternative article and accessories please note that technical data may differ!

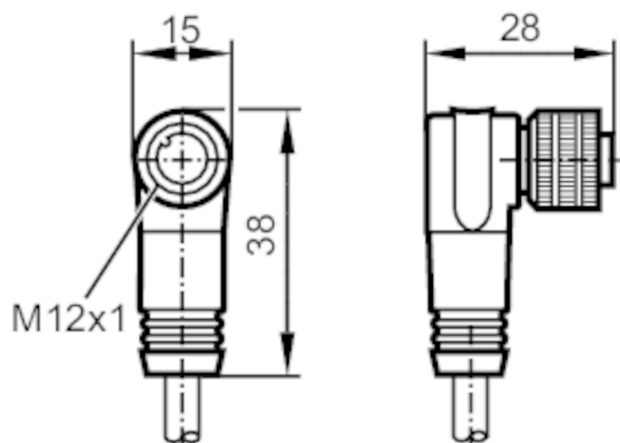

## Application

Special feature	Free from silicone; Gold-plated contacts; Screened cable
Free from silicone	yes

## Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Protection class		III
Max. current load total	[A]	4

## Operating conditions

Ambient temperature	[°C]	-40...85
Protection		IP 67

## Mechanical data

Weight	[g]	236
Dimensions	[mm]	28 x 15 x 38
Materials		PUR
Moulded-body material		PUR
Material nut		stainless steel

## Remarks

Pack quantity		1 pcs.
---------------	--	--------

# E12351



## Connecting cable with socket


ADOAH050MSS0005K05

### Electrical connection


Cable: 5 m, PUR, black, Ø 5.3 mm, shielded; 5 x 0.25 mm<sup>2</sup> (14 x Ø 0.15 mm )

### Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: stainless steel; Contacts: gold-plated; Tightening torque: 1.0...1.5 Nm; Shielded connection cable: screen connected

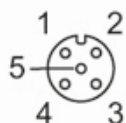

### Connection

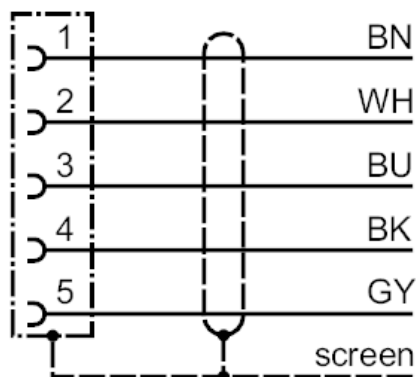

Core colours :	
BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white