


E18430



Sensor testpak

SENSOR TESTPAK

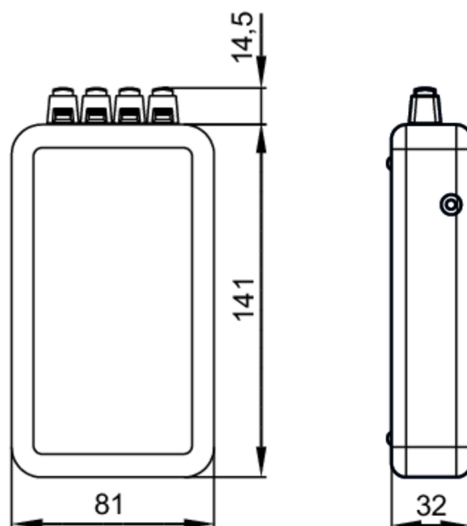

Electrical data

Input voltage DC	[V]	4.5
Output voltage DC	[V]	18

Outputs

Output current, total	[A]	0.04
-----------------------	-----	------

Operating conditions

Ambient temperature	[°C]	-20...40
Protection		IP 21

Tests / approvals

MTTF	[ANN]	341
------	-------	-----

Mechanical data

Weight	[g]	393.3
Dimensions	[mm]	141 x 82 x 34
Materials		ABS; silicone

Displays / operating elements

Display	подача напруги	green
	Display switching status	yellow
Operating elements	membrane key	ON / OFF
	membrane key	Teach

Аксессуары

Accessory required	battery 3 x AA / 1,5 V
--------------------	------------------------

Remarks

Pack quantity	1 pcs.
---------------	--------

E18430




Sensor testpak

SENSOR TESTPAK

Electrical connection

quick-press terminal: 4 x

Connection

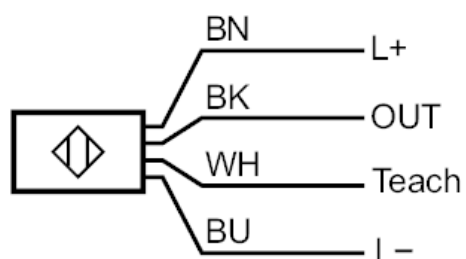

BN	: brown
BK	: black
WH	: white
BU	: blue