


# E18001



## Connecting cable with socket

ADOGH040MKS0010X04

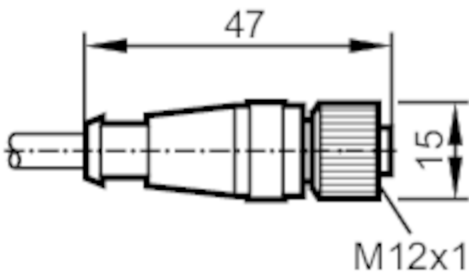

| Application           |      |                      |
|-----------------------|------|----------------------|
| Special feature       |      | Gold-plated contacts |
| Electrical data       |      |                      |
| Operating voltage     | [V]  | < 300 AC/DC          |
| Operating conditions  |      |                      |
| Ambient temperature   | [°C] | -45...105            |
| Protection            |      | IP 68                |
| Mechanical data       |      |                      |
| Weight                | [g]  | 361.966              |
| Dimensions            | [mm] | 15 x 15 x 47         |
| Materials             |      | TPE                  |
| Moulded-body material |      | TPE                  |
| Material nut          |      | zinc, epoxy coated   |
| Remarks               |      |                      |
| Pack quantity         |      | 1 pcs.               |

# E18001



## Connecting cable with socket

ADOGH040MKS0010X04

### Electrical connection


Cable: 10 m, TPE-S, black; 4 x 0.75 mm<sup>2</sup> / AWG 18

### Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPE; Locking: zinc, epoxy coated; Contacts: gold-plated



### Connection

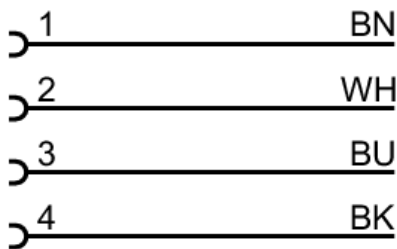

|      |                |
|------|----------------|
|      | Core colours : |
| BK = | black          |
| BN = | brown          |
| BU = | blue           |
| WH = | white          |