


E18031



Wirable socket

SDOGH040MSSFKPG

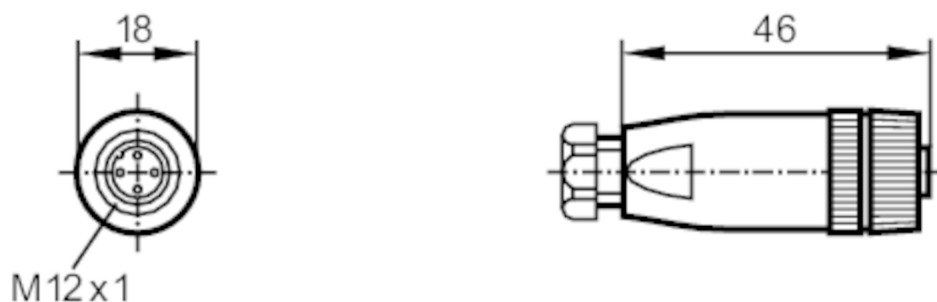

Application

Special feature	Gold-plated contacts
-----------------	----------------------

Electrical data

Operating voltage	[V]	< 250 AC/DC
Max. current load total	[A]	4; (...40 °C)

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	27.216
Dimensions	[mm]	18 x 18 x 46
Materials		PA
Moulded-body material		PA
Material nut		ZnAl / Ni

Remarks

Pack quantity	1 pcs.
---------------	--------

E18031



Wirable socket

SDOGH040MSSFKPG

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 8...10 mm

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: ZnAl / Ni; Contacts: gold-plated



Connection

