


E18045




Connection cable

VSTGH050VAS00.3E03VDAA030--S

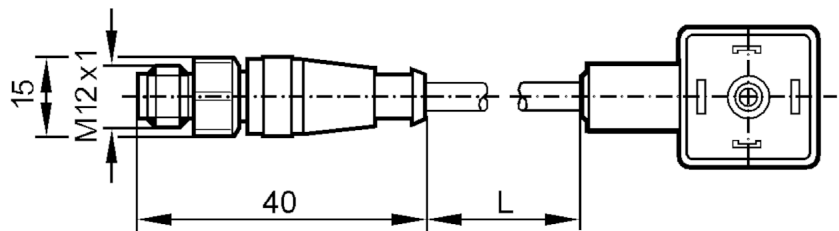

Application		
Special feature	Gold-plated contacts	
Electrical data		
Frequency AC	[Hz]	47...63
Operating voltage	[V]	< 24 AC/DC
Operating conditions		
Ambient temperature	[°C]	-20...105
Protection	IP 68	
Mechanical data		
Weight	[g]	54.431
Materials	TPE	
Moulded-body material	TPE	
Material nut	stainless steel (1.4571/316Ti)	
Remarks		
Pack quantity	1 pcs.	
Electrical connection - plug		

Connector: 1 x M12, straight; coding: A; Moulded body: TPE; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated

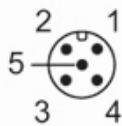




Connection cable

VSTGH050VAS00.3E03VDAA030--S

Electrical connection

Cable: 0.3 m, PVC, grey; 3 x 0.34 mm² / AWG 22

Connection

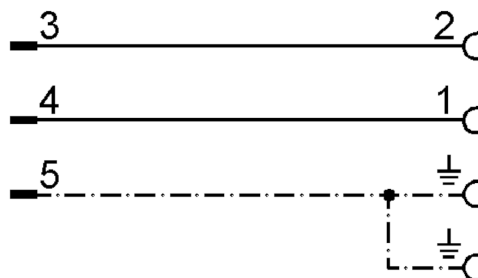

Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPE; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated

