


Adapter plug

RSTGB030VAS00.3-03

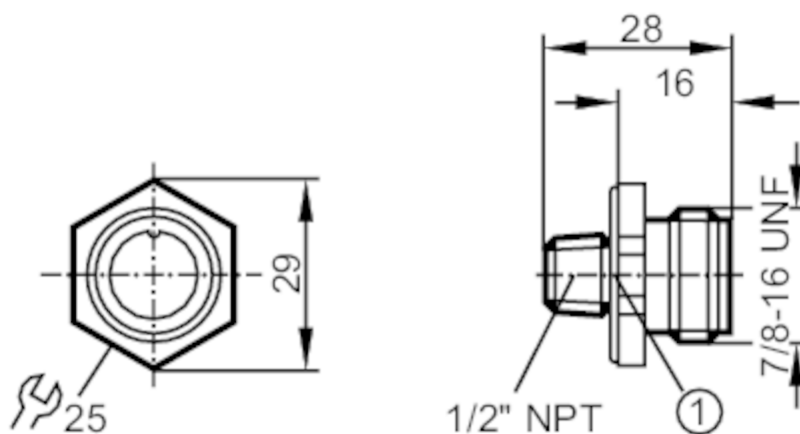

1 O-ring

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage

[V]

< 600 AC/DC

Operating conditions

Ambient temperature

[°C]

-20...100

Protection

IP 68

Mechanical data

Weight

[g]

25.855

Mounting thread

1/2" NPT

Materials

stainless steel

Moulded-body material

stainless steel

Remarks

Pack quantity

1 pcs.

E18055



Adapter plug

RSTGB030VAS00.3-03

Electrical connection

Cable: 0.3 m, PVC; 3 x 1.5 mm² / AWG 16

Electrical connection - plug

Connector: 1 x 7/8", straight; coding: A; Moulded body: stainless steel; Contacts: gold-plated



Connection

1	GN
2	RD
3	BK

BK = Core colours :
GN = black
RD = green
 red