


Adapter plug

RSTGB050PLS00.3-05

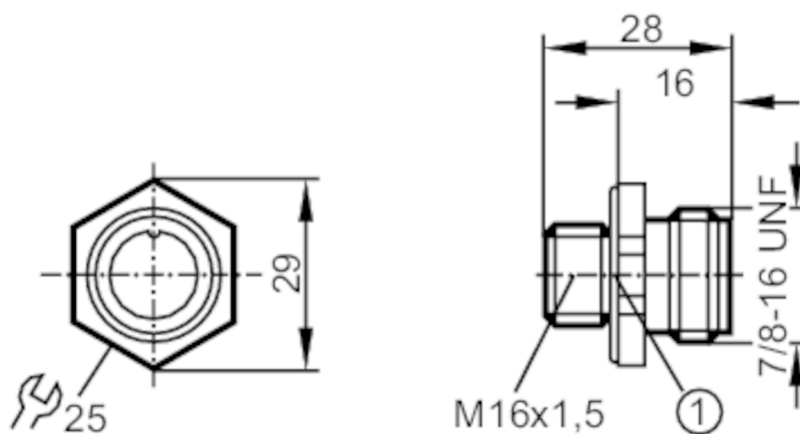

1 O-ring

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage

[V]

< 600 AC/DC

Operating conditions

Ambient temperature

[°C]

-20...100

Protection

IP 68

Mechanical data

Weight

[g]

27.216

Mounting thread

M16 x 1,5

Materials

plastics

Moulded-body material

plastics

Remarks

Pack quantity

1 pcs.

E18072



Adapter plug


RSTGB050PLS00.3-05

Electrical connection

Cable: 0.3 m, PVC; 5 x 1.5 mm² / AWG 16

Electrical connection - plug

Connector: 1 x 7/8", straight; coding: A; Moulded body: plastics; Contacts: gold-plated

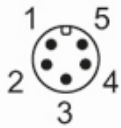

Connection

1	WH
2	RD
3	BU
4	OG
5	BK

	Core colours :
BK =	black
BU =	blue
RD =	red
OG =	orange
WH =	white