




Connecting cable with socket

ADOGH040VAS0012E04

Article no longer available - archive entry

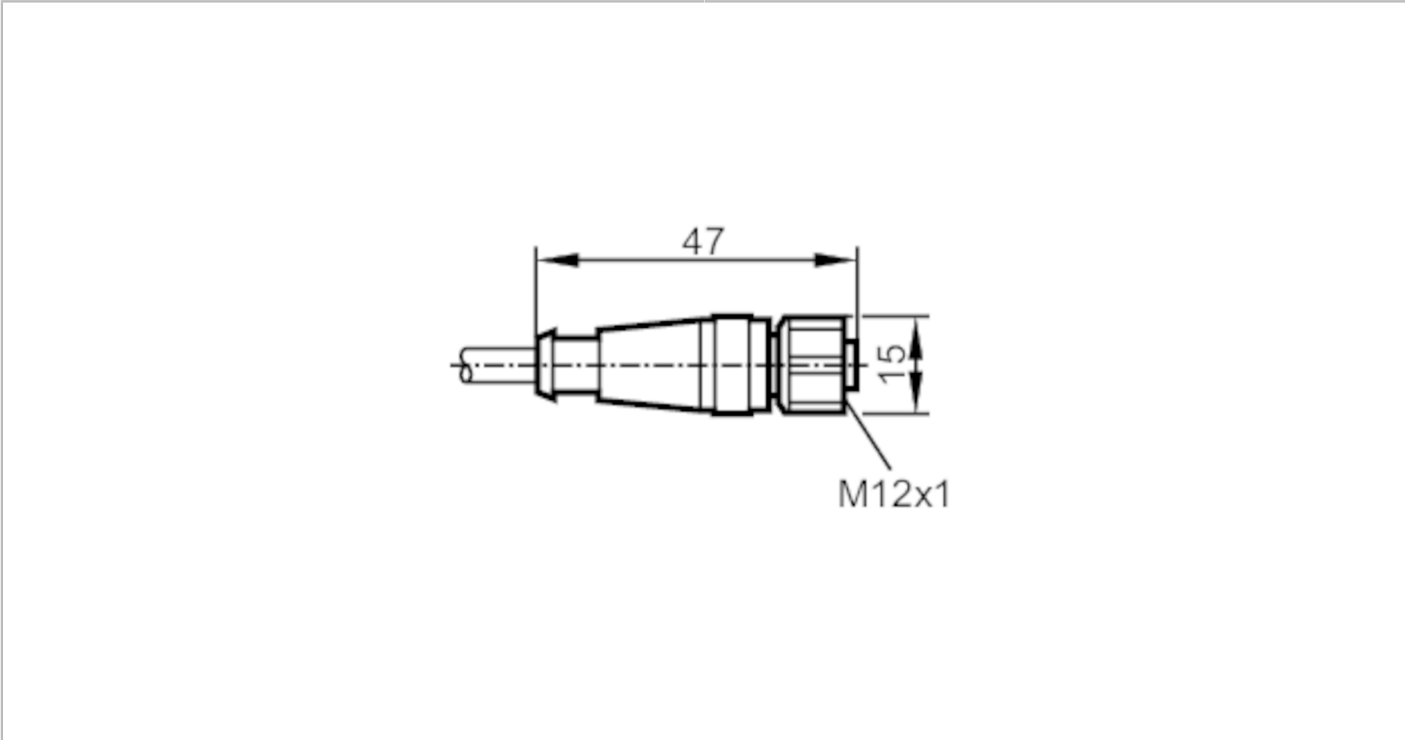

Application		
Special feature		Gold-plated contacts
Electrical data		
Operating voltage	[V]	< 300 AC/DC
Operating conditions		
Ambient temperature	[°C]	-20...105
Protection		IP 68
Mechanical data		
Weight	[g]	299.371
Dimensions	[mm]	15 x 15 x 47
Materials		PVC
Moulded-body material		PVC
Material nut		stainless steel (1.4571/316Ti)
Remarks		
Pack quantity		1 pcs.

E18106



Connecting cable with socket


ADOGH040VAS0012E04

Electrical connection

Cable: 12 m, PVC, grey, Ø 5 mm; 4 x 0.34 mm² / AWG 22

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated

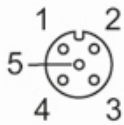

Connection



5: not used
Core colours :
BK = black
BN = brown
BU = blue
WH = white