




Connection cable

VDOGH040VAS00.4E03STGH040VAS

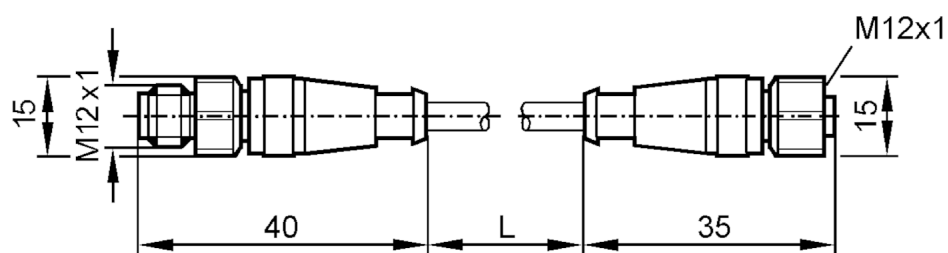

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage

[V]

< 300 AC/DC

Operating conditions

Ambient temperature

[°C]

-20...105

Protection

IP 68

Mechanical data

Weight

[g]

45.359

Dimensions

[mm]

15 x 15 x 40

Materials

PVC

Moulded-body material

PVC

Material nut

stainless steel (1.4571/316Ti)


Remarks

Pack quantity

1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated

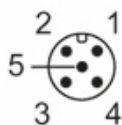

E18127



Connection cable

VDOGH040VAS00.4E03STGH040VAS

Electrical connection

Cable: 0.4 m, PVC, grey; 3 x 0.34 mm² / AWG 22

Connection



Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated

