


E18128



Connection cable


VDOGH040VAS00.5E03STGH040VAS

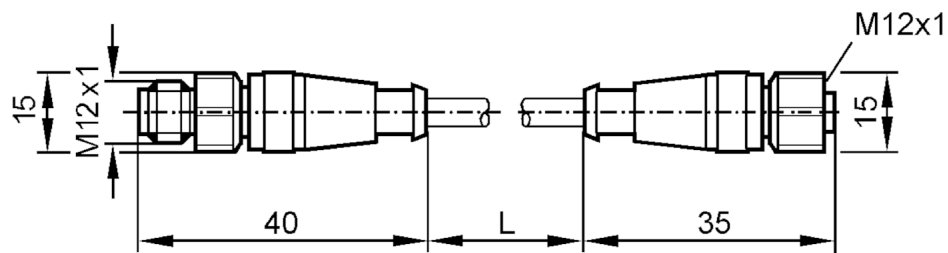

Application	
Special feature	Gold-plated contacts
Electrical data	
Operating voltage [V]	< 300 AC/DC
Operating conditions	
Ambient temperature [°C]	-20...105
Protection	IP 68
Mechanical data	
Weight [g]	45.359
Dimensions [mm]	15 x 15 x 40
Materials	PVC
Moulded-body material	PVC
Material nut	stainless steel (1.4571/316Ti)
Remarks	
Pack quantity	1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated

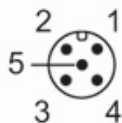

E18128




Connection cable

VDOGH040VAS00.5E03STGH040VAS

Electrical connection

Cable: 0.5 m, PVC, grey; 3 x 0.34 mm² / AWG 22

Connection

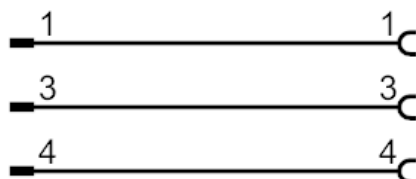

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated

