


E18129



Connecting cable with socket

ADOAH040VAS0060E04

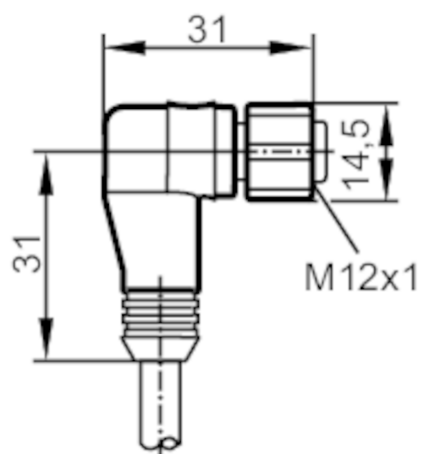

Application	
Special feature	Gold-plated contacts
Electrical data	
Operating voltage [V]	< 300 AC/DC
Operating conditions	
Ambient temperature [°C]	-20...105
Protection	IP 68
Mechanical data	
Weight [g]	2100.131
Dimensions [mm]	31 x 14.5 x 31
Materials	PVC
Moulded-body material	PVC
Material nut	stainless steel (1.4571/316Ti)
Remarks	
Pack quantity	1 pcs.

E18129



Connecting cable with socket

ADOAH040VAS0060E04

Electrical connection

Cable: 60 m, PVC, grey; 4 x 0.34 mm² / AWG 22

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PVC; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated



Connection



5: not used
Core colours :
BK = black
BN = brown
BU = blue
WH = white