


E18149



Connecting cable with socket

ADOAH040MSS0002X04

Article no longer available - archive entry

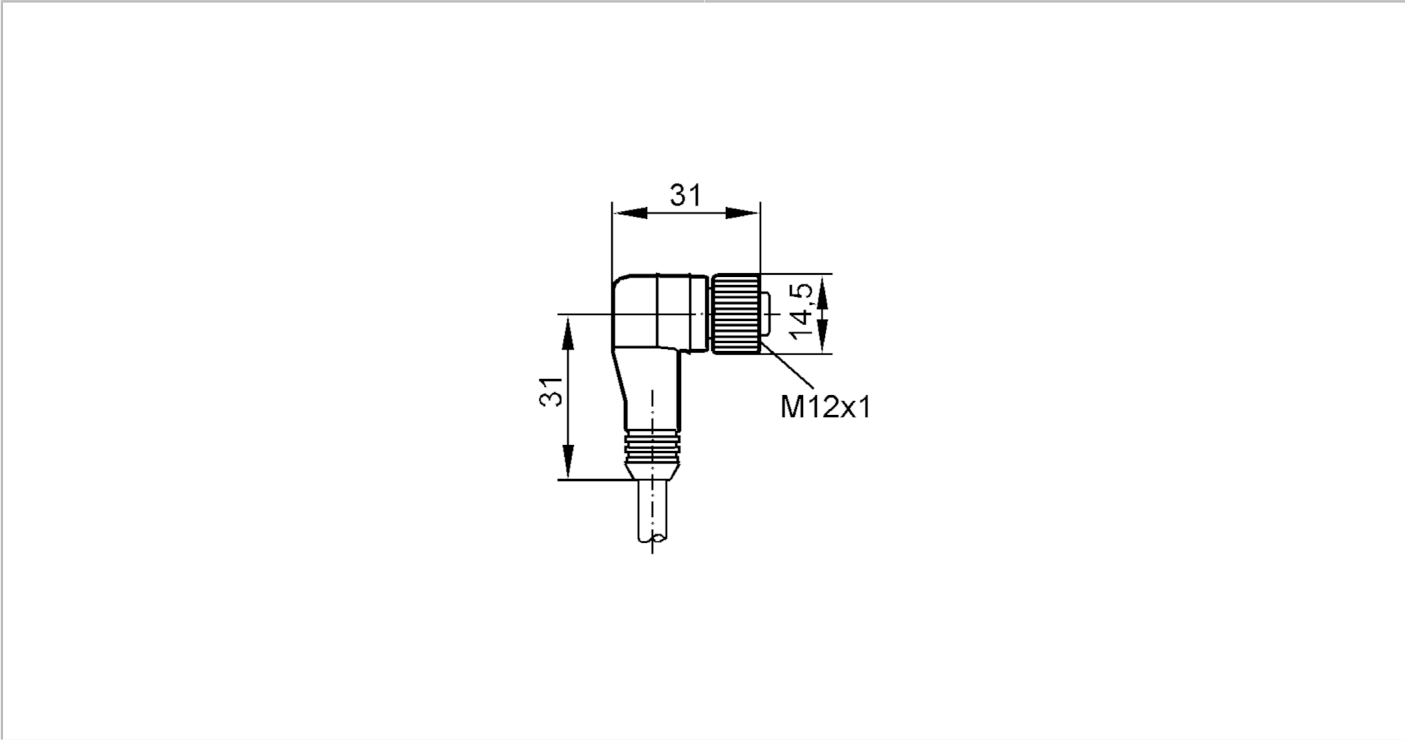

Application		
Special feature		Gold-plated contacts
Electrical data		
Operating voltage	[V]	< 300 AC/DC
Operating conditions		
Ambient temperature	[°C]	-45...105
Protection		IP 68
Mechanical data		
Weight	[g]	158.757
Dimensions	[mm]	31 x 14.5 x 31
Materials		TPE
Moulded-body material		TPE
Material nut		zinc, epoxy coated
Remarks		
Pack quantity		1 pcs.

E18149



Connecting cable with socket

 
ADOAH040MSS0002X04

Electrical connection


Cable: 2 m, TPE-S, black; 4 x 0.75 mm² / AWG 18

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPE; Locking: zinc, epoxy coated; Contacts: gold-plated



Connection

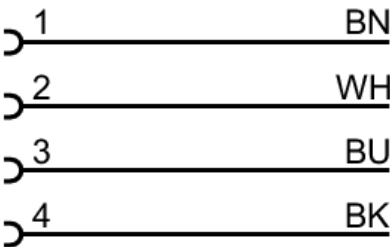

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white