


Adapter socket

RDOGF040MSS00.3-04

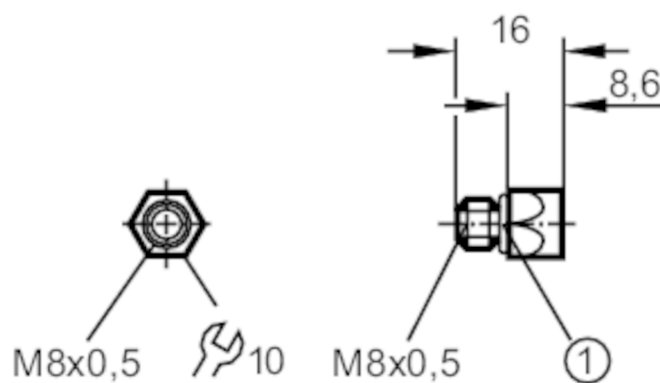

1 O-ring



Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-20...100
Protection		IP 68

Mechanical data

Weight	[g]	113.398
Materials		housing: brass nickel-plated; Sealing: FKM; Lock nut: brass nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E18177



Adapter socket

RDOGF040MSS00.3-04

Electrical connection


Cable: 0.5 m, PVC, yellow, Ø 4.6 mm; 4 x 0.25 mm² / AWG 24

Electrical connection - socket

Connector: 1 x M8; coding: A



Connection

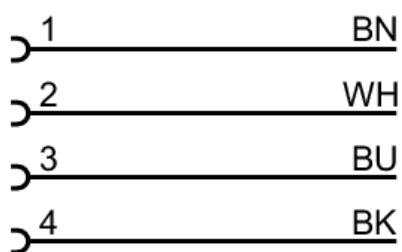

BK =	Core colours :
BN =	black
BU =	brown
WH =	blue
	white