


Connection cable

VDOAH040VAS02.5E03STGH040VAS

Article no longer available - archive entry

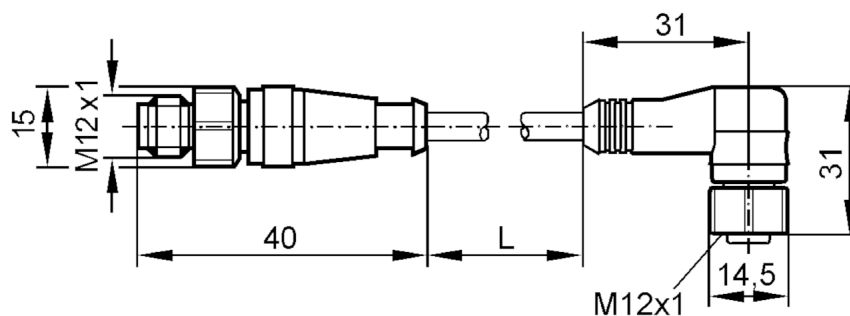

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage

[V]

< 300 AC/DC

Operating conditions

Ambient temperature

[°C]

-20...105

Protection

IP 68

Mechanical data

Weight

[g]

63.503

Materials

TPE

Moulded-body material

TPE

Material nut

stainless steel (1.4571/316Ti)

Remarks

Pack quantity

1 pcs.



Connection cable


VDOAH040VAS02.5E03STGH040VAS

Electrical connection

Cable: 2.5 m, PVC, grey; 3 x 0.34 mm² / AWG 22


Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPE; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated

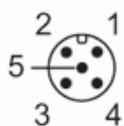

Electrical connection

Connection

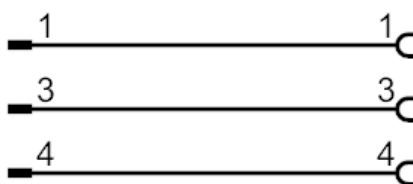

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPE; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated

