




Adapter socket

RDOGH050MSS00.3E05

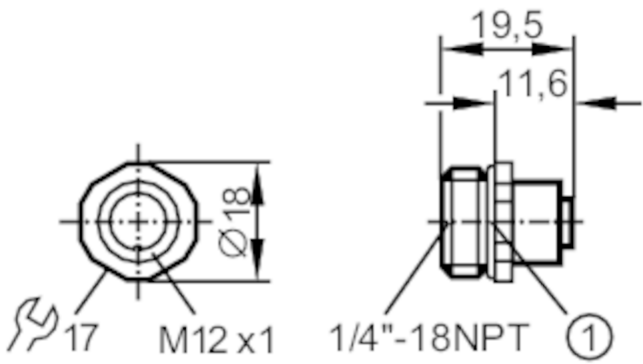

1 O-ring

Electrical data

Operating voltage	[V]	< 250 AC/DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Weight	[g]	22.68
Mounting thread		1/4\"-18NPT
Materials		brass nickel-plated
Moulded-body material		brass, nickel-plated

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 0.5 m, PVC; 5 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M12; coding: A; Moulded body: brass, nickel-plated

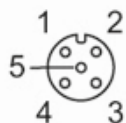


E18327



Adapter socket

RDOGH050MSS00.3E05

Connection

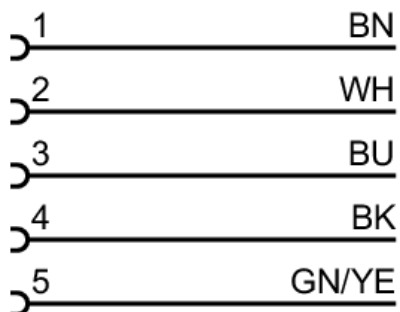

	Core colours :
BK =	black
BN =	brown
BU =	blue
GN/YE =	green/yellow
WH =	white