


E19901



Splitter box

ZDO6H040MSS0010A09

Article no longer available - archive entry

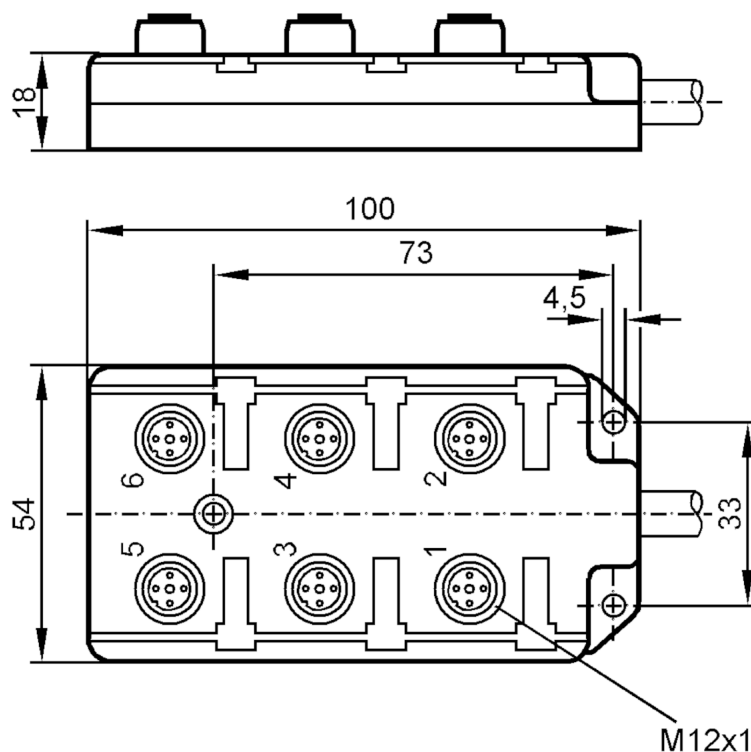

Electrical data

Operating voltage	[V]	10...110 AC/DC
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12

Operating conditions

Ambient temperature	[°C]	-15...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	18 x 54 x 100
Number of ports splitter box		6

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E19901



Splitter box

ZDO6H040MSS0010A09

Electrical connection

Cable: 10 m, PUR / PVC; 6 x 0.34 mm² + 3 x 0.75 mm²

Electrical connection - slot

Connector: 6 x M12; coding: A



Connection

BN	1 (1...6)
BU	3 (1...6)
GN/YE	5 (1...6)
WH	4 (1)
GN	4 (2)
YE	4 (3)
GY	4 (4)
PK	4 (5)
RD	4 (6)

	Core colours :
BN =	brown
BU =	blue
GN =	green
GN/YE =	green/yellow
GY =	grey
PK =	pink
RD =	red
WH =	white
YE =	yellow