


E19908

Splitter box

ZDO8H040MSS0010B11



Article no longer available - archive entry

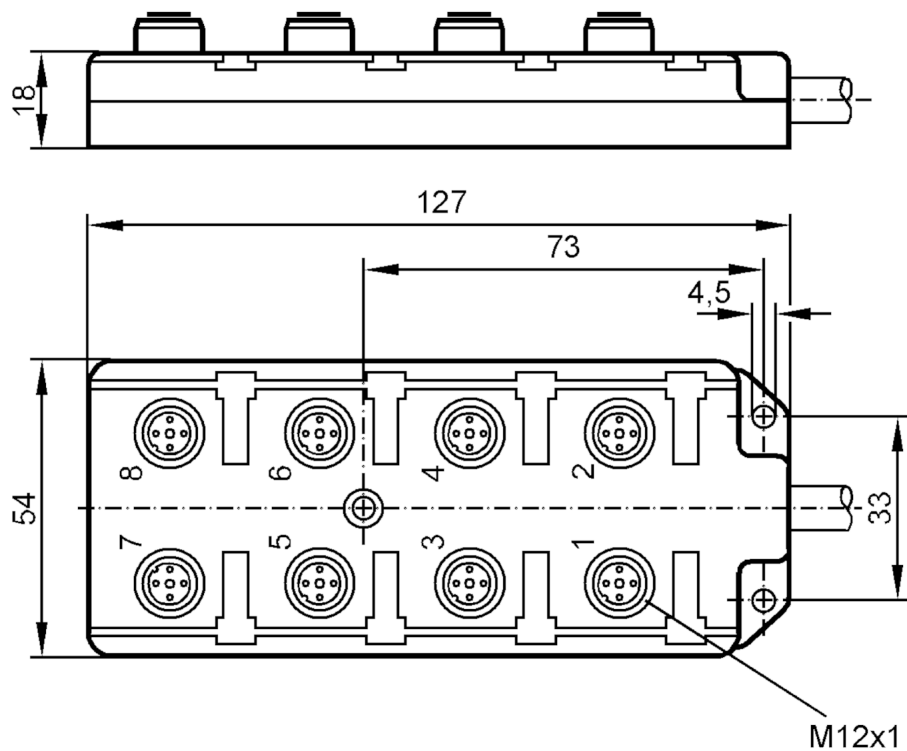

Electrical data

Operating voltage	[V]	10...110 AC/DC
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12

Operating conditions

Ambient temperature	[°C]	-15...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	16 x 54 x 127
Number of ports splitter box		8

Remarks

Pack quantity	1 pcs.
---------------	--------

E19908



Splitter box

ZDO8H040MSS0010B11

Electrical connection

Cable: 10 m, PUR / PVC; 8 x 0.34 mm² + 3 x 0.75 mm²

Electrical connection - slot

Connector: 8 x M12; coding: A



Connection

BN	1 (1...8)	C
BU	3 (1...8)	C
GN/YE	5 (1...8)	C
WH	4 (1)	C
GN	4 (2)	C
YE	4 (3)	C
GY	4 (4)	C
PK	4 (5)	C
RD	4 (6)	C
BK	4 (7)	C
VT	4 (8)	C

	Core colours :
BK =	black
BN =	brown
BU =	blue
GN =	green
GN/YE =	green/yellow
GY =	grey
PK =	pink
RD =	red
VT =	lilac
WH =	white
YE =	yellow