


# E19910



## Splitter box

ZDO4H040MSS0010A07

Article no longer available - archive entry

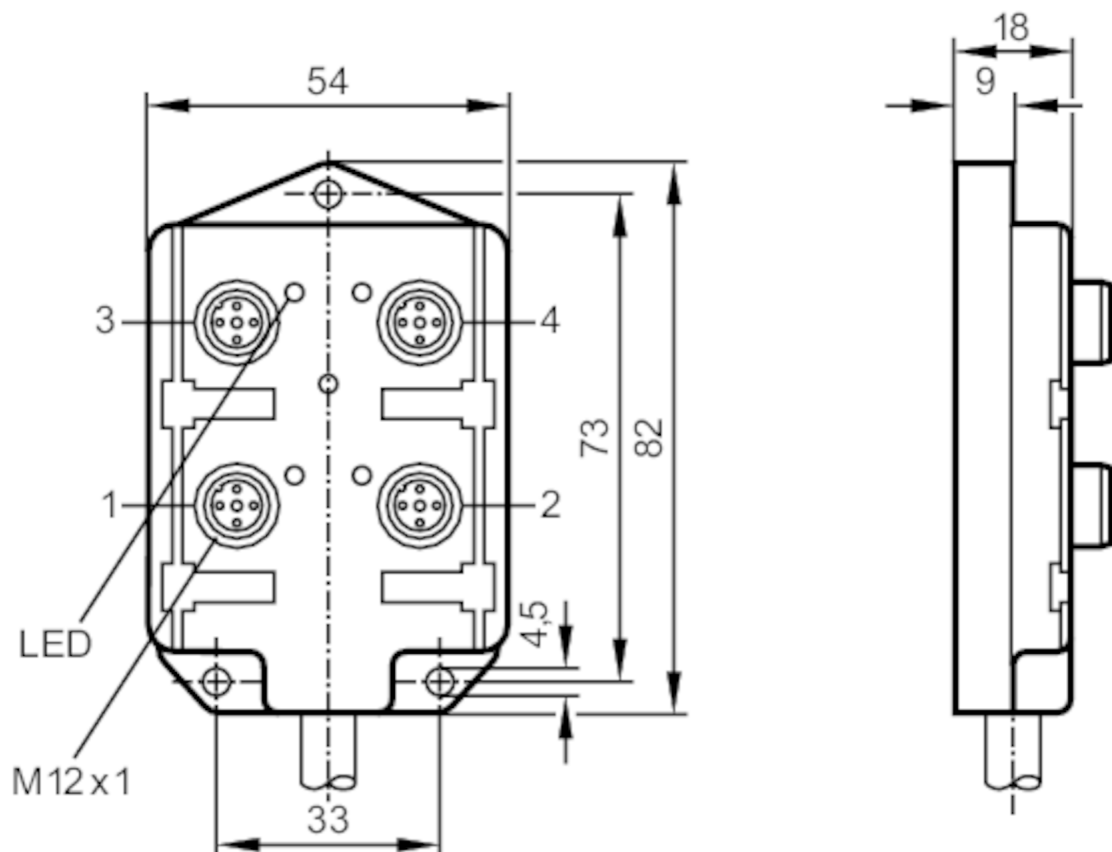

### Electrical data

|                                   |     |                |
|-----------------------------------|-----|----------------|
| Operating voltage                 | [V] | 10...110 AC/DC |
| Max. current load per module/slot | [A] | 4              |
| Max. current load total           | [A] | 12             |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -15...90 |
| Protection          |      | IP 67    |

### Mechanical data

|                              |      |              |
|------------------------------|------|--------------|
| Dimensions                   | [mm] | 18 x 54 x 82 |
| Number of ports splitter box |      | 4            |

### Remarks

|               |  |        |
|---------------|--|--------|
| Pack quantity |  | 1 pcs. |
|---------------|--|--------|

# E19910



## Splitter box


ZDO4H040MSS0010A07

### Electrical connection

Cable: 10 m, PUR / PVC; 4 x 0.34 mm<sup>2</sup> + 3 x 0.75 mm<sup>2</sup>

### Electrical connection - slot

Connector: 4 x M12; coding: A

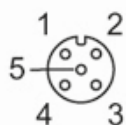

### Connection

|       |           |   |
|-------|-----------|---|
| BN    | 1 (1...4) | C |
| BU    | 3 (1...4) | C |
| GN/YE | 5 (1...4) | C |
| WH    | 4 (1)     | C |
| GN    | 4 (2)     | C |
| YE    | 4 (3)     | C |
| GY    | 4 (4)     | C |

|         |                |
|---------|----------------|
|         | Core colours : |
| BN =    | brown          |
| BU =    | blue           |
| GN =    | green          |
| GN/YE = | green/yellow   |
| GY =    | grey           |
| WH =    | white          |
| YE =    | yellow         |