


E19939

Splitter box

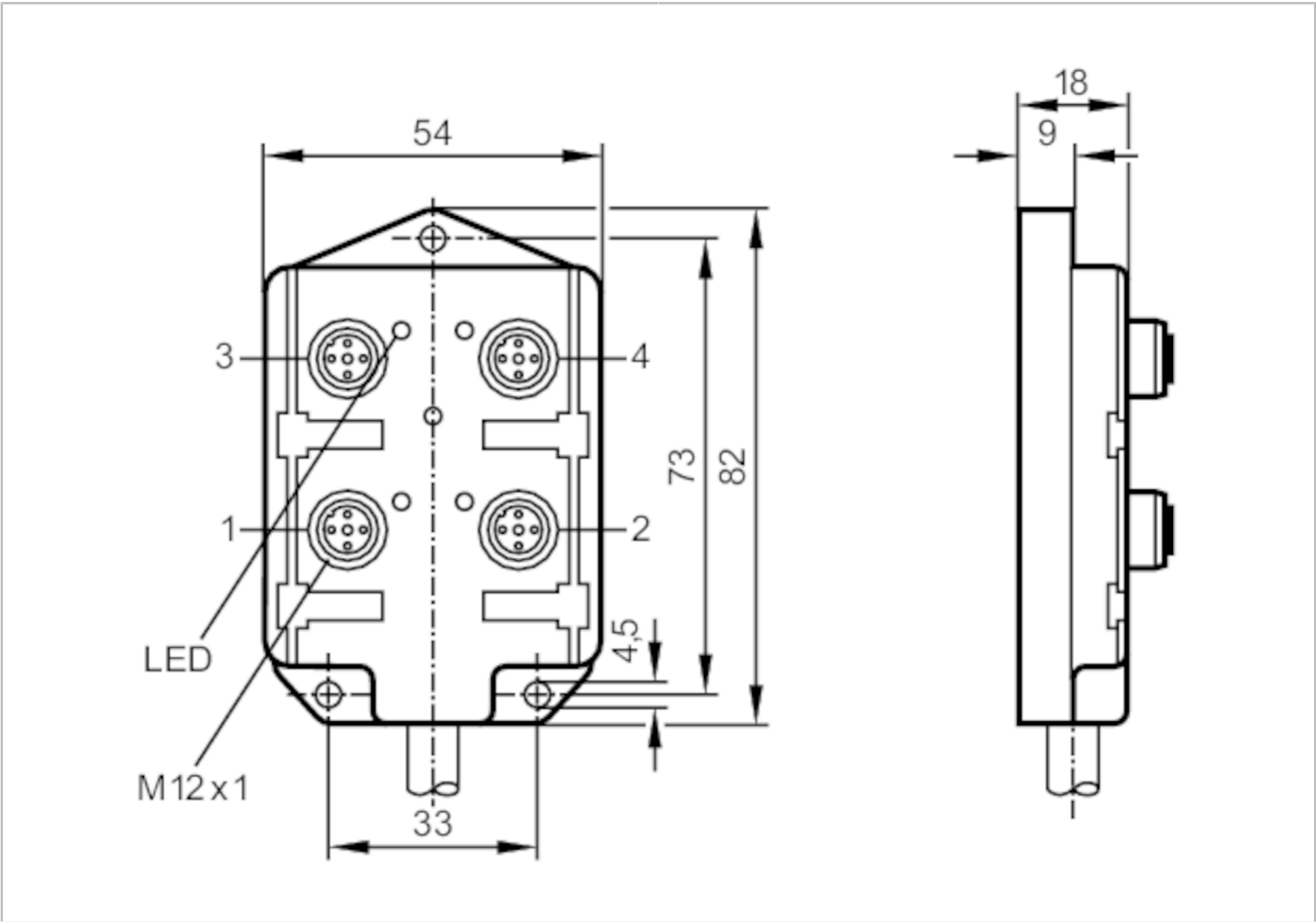

Electrical data		
Operating voltage	[V]	10...110 AC/DC
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12
Operating conditions		
Ambient temperature	[°C]	-15...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	18 x 54 x 82
Number of ports splitter box		4
Remarks		
Pack quantity		1 pcs.




Splitter box

Electrical connection

Cable: 5 m, PUR / PVC; 4 x 0.34 mm² + 3 x 0.75 mm²

Electrical connection - slot

Connector: 4 x M12; coding: A

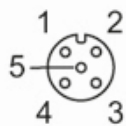

Connection

BN	1 (1...4)	C
BU	3 (1...4)	C
GN/YE	5 (1...4)	C
WH	4 (1)	C
GN	4 (2)	C
YE	4 (3)	C
GY	4 (4)	C

	Core colours :
BN =	brown
BU =	blue
GN =	green
GN/YE =	green/yellow
GY =	grey
WH =	white
YE =	yellow