

E20410




Fibre optic diffuse reflection sensor

FT-00-A-V-E1/0,25M

Article no longer available - archive entry

Alternative articles: E20057
When selecting an alternative article and accessories please note that technical data may differ!

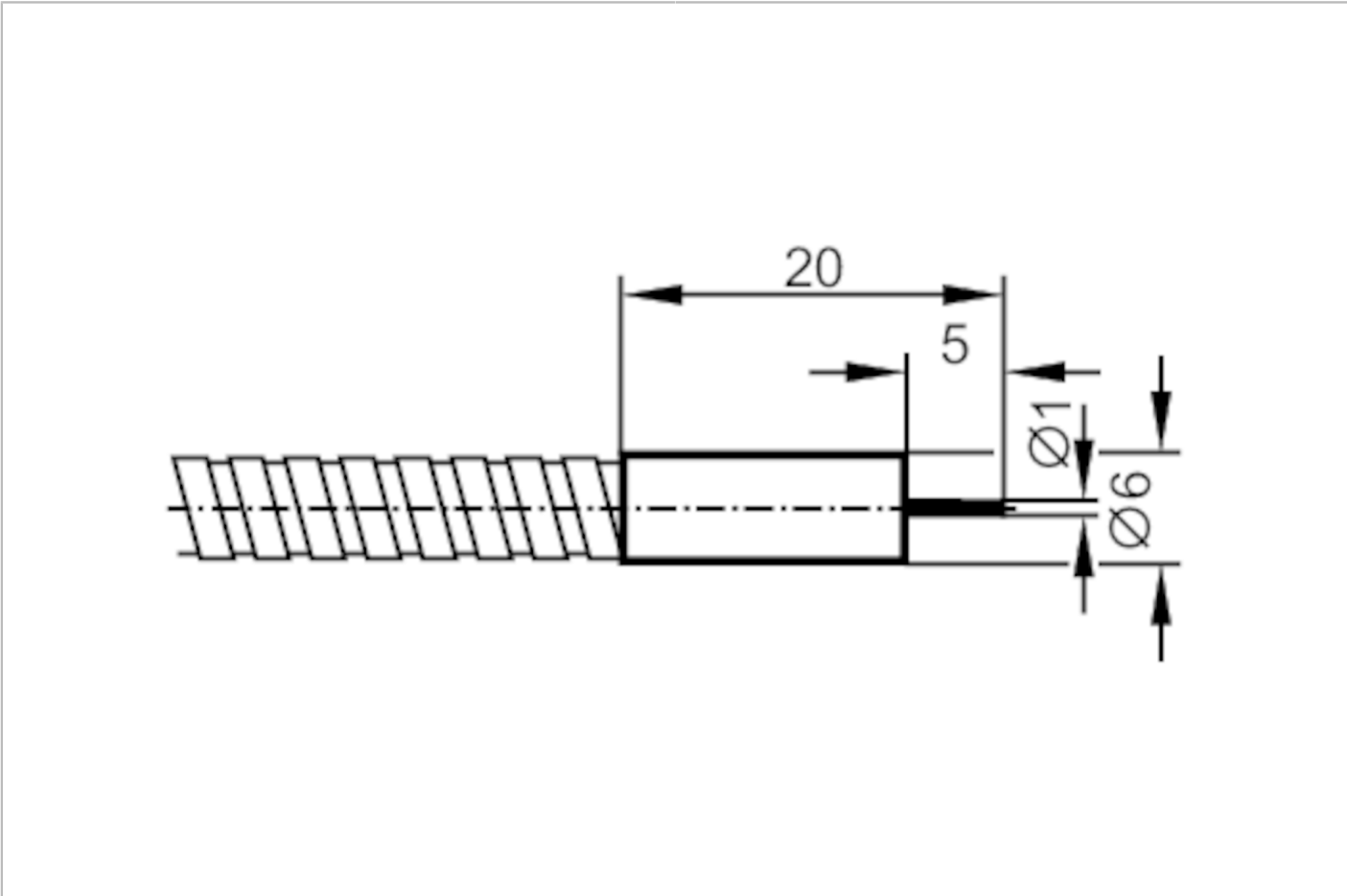

Application	
Function principle	Diffuse reflection sensor
Detection zone	
Range with fibre optic amplifier type	OKF; OUF
OKF	
Range fibre optics [mm]	8
OUF	
Range fibre optics [mm]	8
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Version of sensing head	straight
Sensing head diameter [mm]	1
Sensing head length [mm]	5
Total length [mm]	250

E20410



Fibre optic diffuse reflection sensor

FT-00-A-V-E1/0,25M

Min. bending radius	[mm]	20
Materials	Adapter: ABS	
Fibre material	glass	
Fibre head material	stainless steel (303/1.4305)	
Fibre sheath material	aluminium	
Remarks		
Pack quantity	1 pcs.	