




Fibre optic diffuse reflection sensor

FT-00-P-A-R4/0,22M

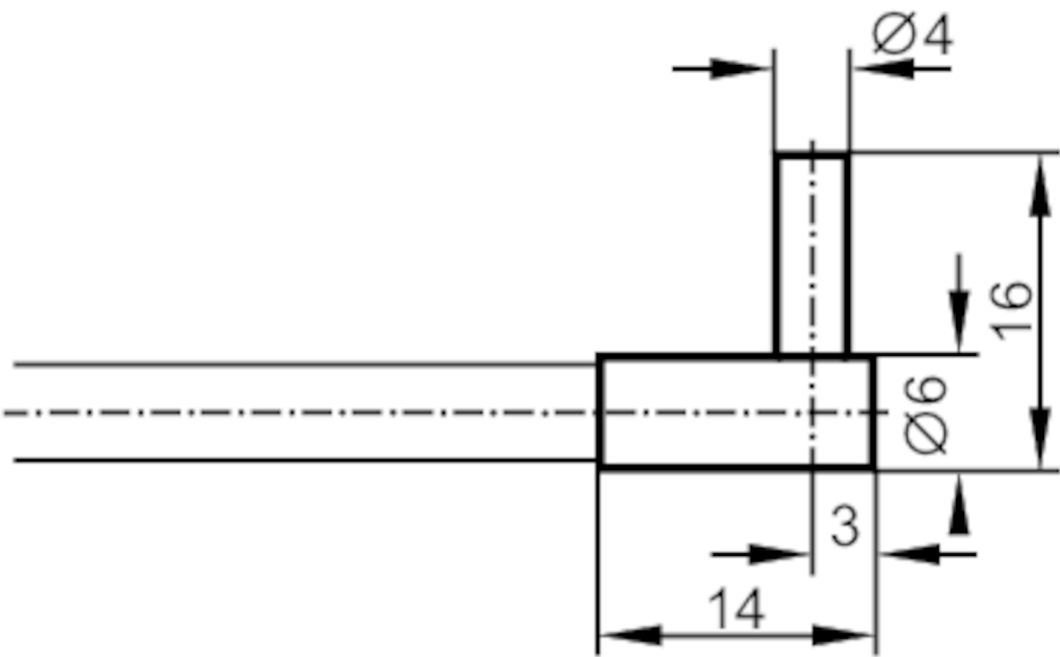

Application		
Function principle		Diffuse reflection sensor
Application		Для використання у промисловості
Detection zone		
Range with fibre optic amplifier type		OKF; OUF
OKF		
Range fibre optics	[mm]	40
OUF		
Range fibre optics	[mm]	40
Operating conditions		
Ambient temperature	[°C]	-20...80
Mechanical data		
Weight	[g]	41.5
Version of sensing head		angled
Sensing head diameter	[mm]	4
Sensing head length	[mm]	10
Total length	[mm]	220
Min. bending radius	[mm]	20
Fibre arrangement		Ⓢ

E20412



Fibre optic diffuse reflection sensor

FT-00-P-A-R4/0,22M

Materials	Adapter: PPE
Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	PVC
Аксессуары	
Items supplied	E20103
Remarks	
Pack quantity	1 pcs.