


Connecting cable with socket

ADOGB030MSS0005E03

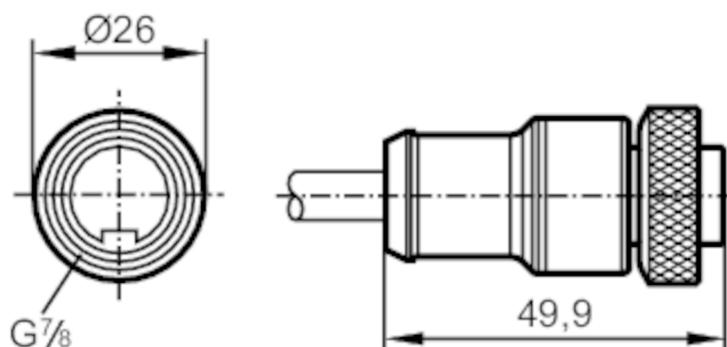

Electrical data

Operating voltage	[V]	< 300 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-30...80
Ambient temperature (moving)	[°C]	-5...80
Protection		IP 68

Mechanical data

Weight	[g]	279.3
Dimensions	[mm]	26 x 26 x 49.9
Moulded-body material		TPU
Material nut		diecast zinc

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E20429



Connecting cable with socket

ADOGB030MSS0005E03

Electrical connection


Cable: 5 m, PVC, black, Ø 5.2 mm; 3 x 0.75 mm² (24 x Ø 0.2 mm)

Electrical connection - socket

Connector: 1 x 7/8", straight; Moulded body: TPU; Locking: diecast zinc



Connection

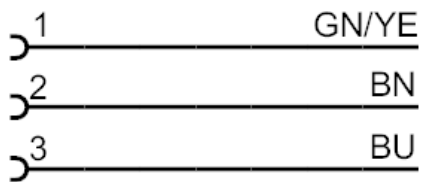

BN = Core colours : brown
BU = blue
GN/YE = green/yellow