




Fibre optic diffuse reflection sensor

FT-00-A-A-E3/0,35M

Article no longer available - archive entry

Alternative articles: E20080
When selecting an alternative article and accessories please note that technical data may differ!

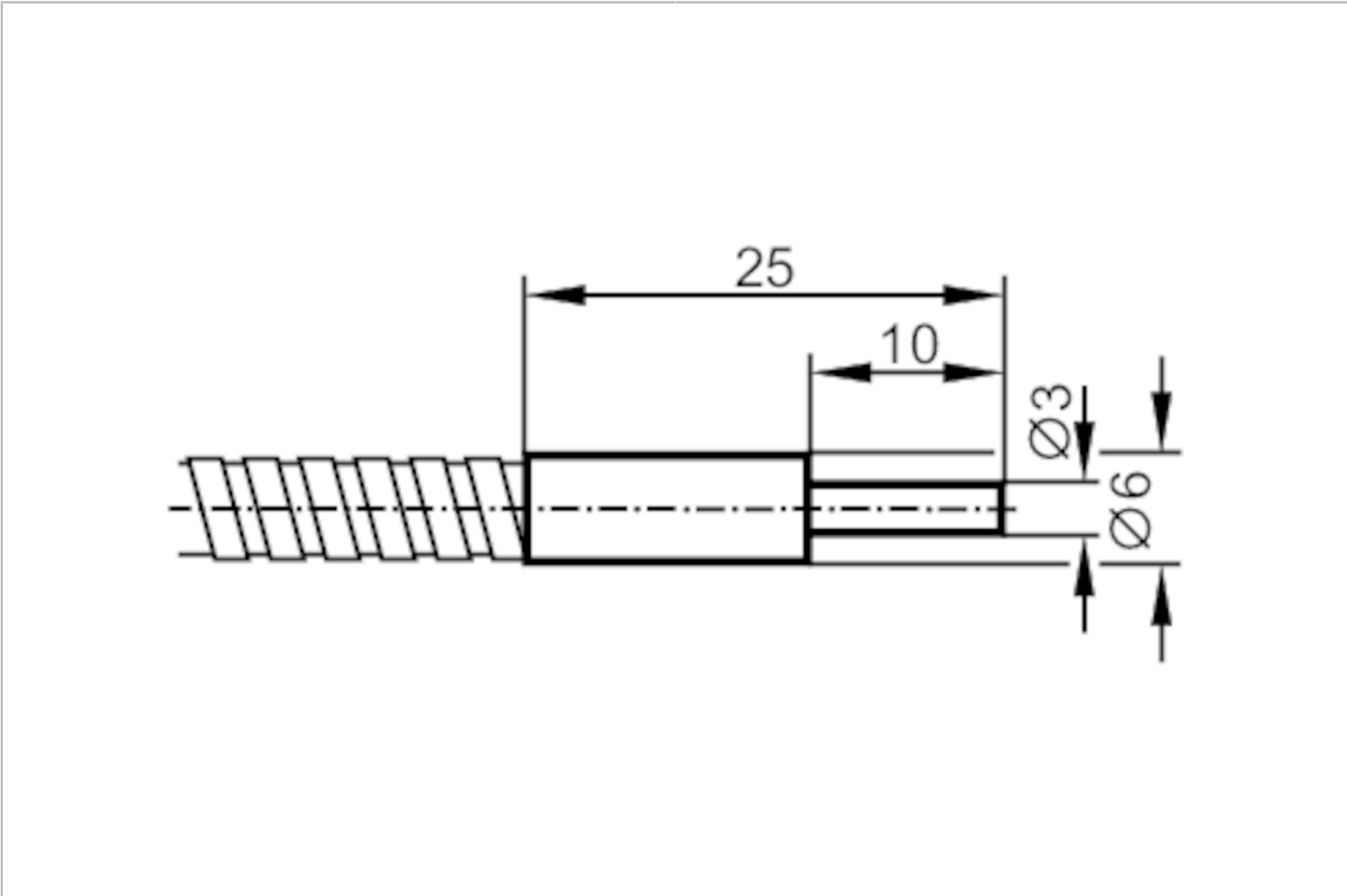

Application	
Function principle	Diffuse reflection sensor
Detection zone	
Range with fibre optic amplifier type	OKF; OUF
OKF	
Range fibre optics [mm]	40
OUF	
Range fibre optics [mm]	40
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Version of sensing head	straight
Sensing head diameter [mm]	3
Sensing head length [mm]	10
Total length [mm]	350

E20442



Fibre optic diffuse reflection sensor

FT-00-A-A-E3/0,35M

Min. bending radius	[mm]	20
Materials		Adapter: ABS
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		aluminium
Аксессуары		
Items supplied		E20102
Remarks		
Pack quantity		1 pcs.