




Fibre optic through-beam sensor

FE-00-P-A-E2,5/0,8M

Article no longer available - archive entry

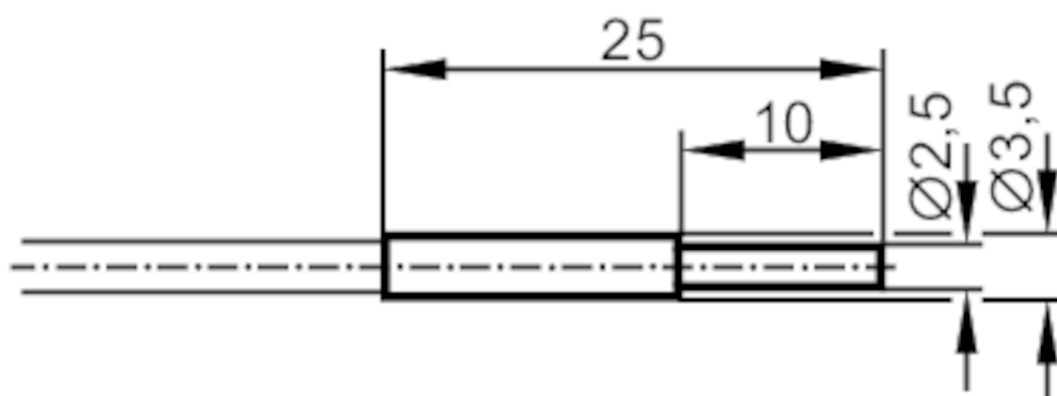

Application

Function principle

Through-beam sensor

Detection zone

Range with fibre-optic
amplifier type

OKF; OUF

OKF

Range of fibre optics

[mm]

120

OUF

Range of fibre optics

[mm]

120

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

2.5

Sensing head length

[mm]

10

Total length

[mm]

800

Min. bending radius

[mm]

10

Materials

Adapter: PPE

Fibre material

glass

E20449



Fibre optic through-beam sensor

FE-00-P-A-E2,5/0,8M

Fibre head material	aluminium
Fibre sheath material	PVC
Аксессуары	
Items supplied	E20106
Remarks	
Pack quantity	1 pcs.