




Connecting cable with socket

ADOAH043MSS0005A04

Article no longer available - archive entry

Alternative articles: EVC008
When selecting an alternative article and accessories please note that technical data may differ!

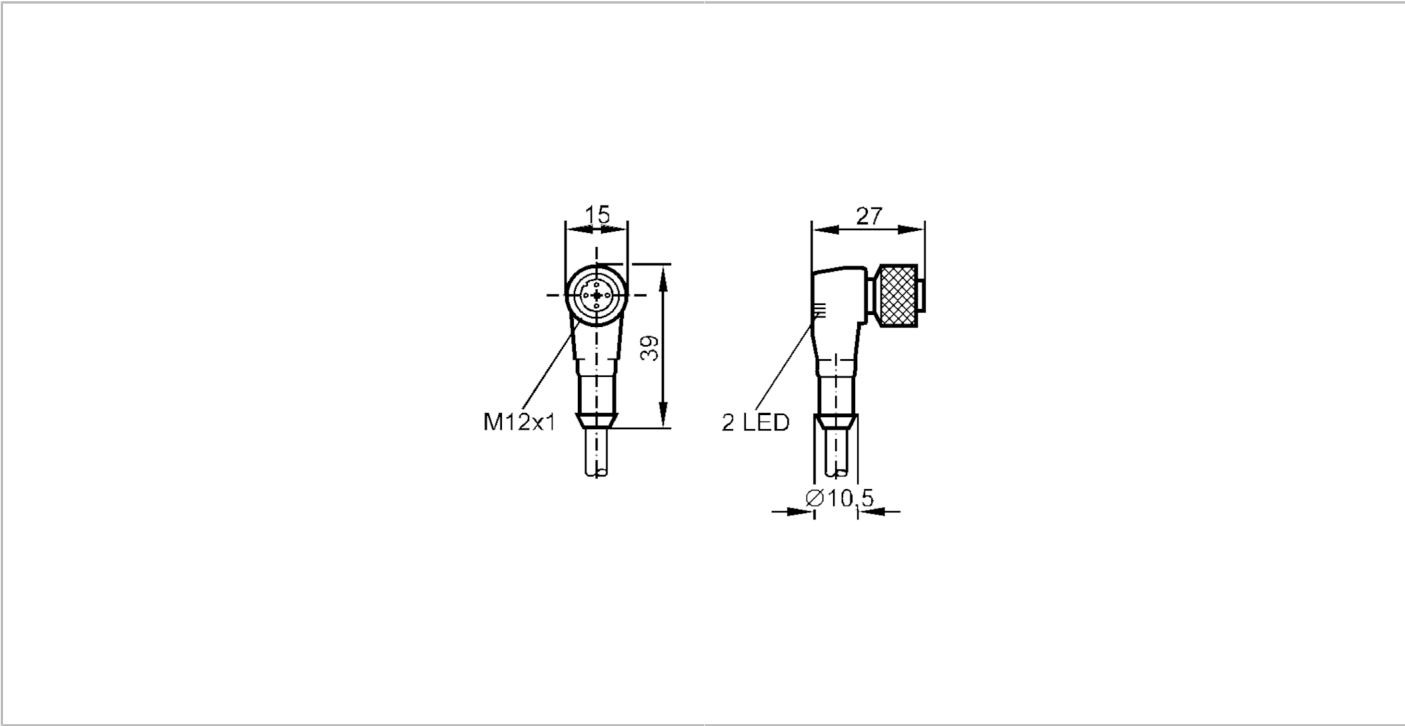

Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	27 x 15 x 39
Materials		TPU transparent
Moulded-body material		TPU, transparent
Material nut		brass, nickel-plated
Displays / operating elements		
Display	switching status	2 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E20479



Connecting cable with socket

ADOAH043MSS0005A04

Electrical connection

Cable: 5 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU, transparent; Locking: brass, nickel-plated



Connection



BK =	Core colours :
BN =	black
BU =	brown
WH =	blue
	white