

E20520




Fibre optic through-beam sensor

FE-00-A-A-R3/0,22M +/-10MM

Article no longer available - archive entry

Alternative articles: E20129
When selecting an alternative article and accessories please note that technical data may differ!

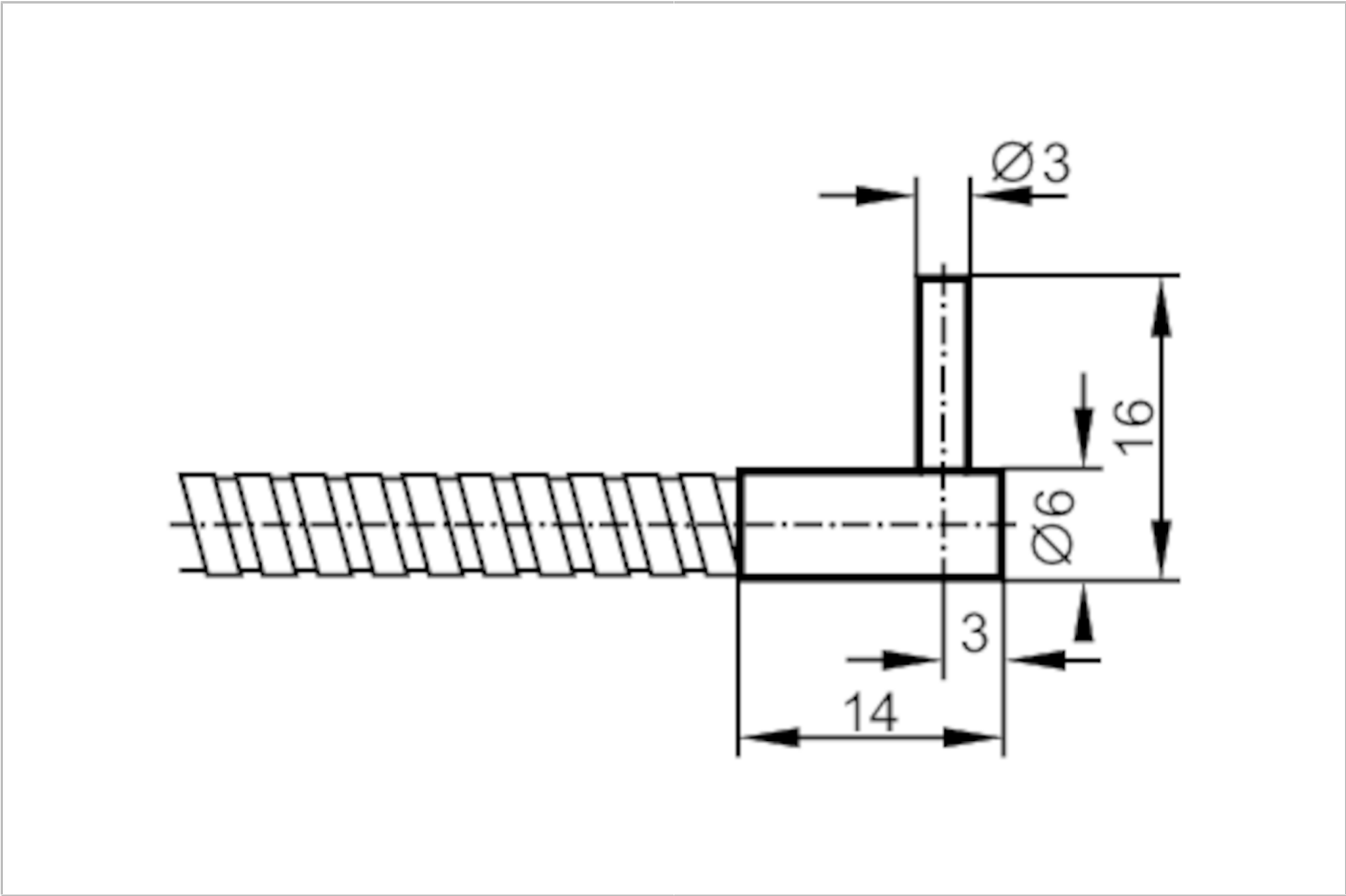

Application	
Function principle	Through-beam sensor
Detection zone	
Range with fibre-optic amplifier type	OKF; OUF
OKF	
Range of fibre optics [mm]	120
OUF	
Range of fibre optics [mm]	120
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Version of sensing head	angled
Sensing head diameter [mm]	3
Sensing head length [mm]	10
Total length [mm]	220; (-10 %)

E20520



Fibre optic through-beam sensor

FE-00-A-A-R3/0,22M +/-10MM

Min. bending radius	[mm]	20
Materials		Adapter: ABS
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		aluminium
Remarks		
Pack quantity		1 pcs.