


Fibre optic diffuse reflection sensor

FT-00-A-A-R4/0,22M +/-10MM

Article no longer available - archive entry

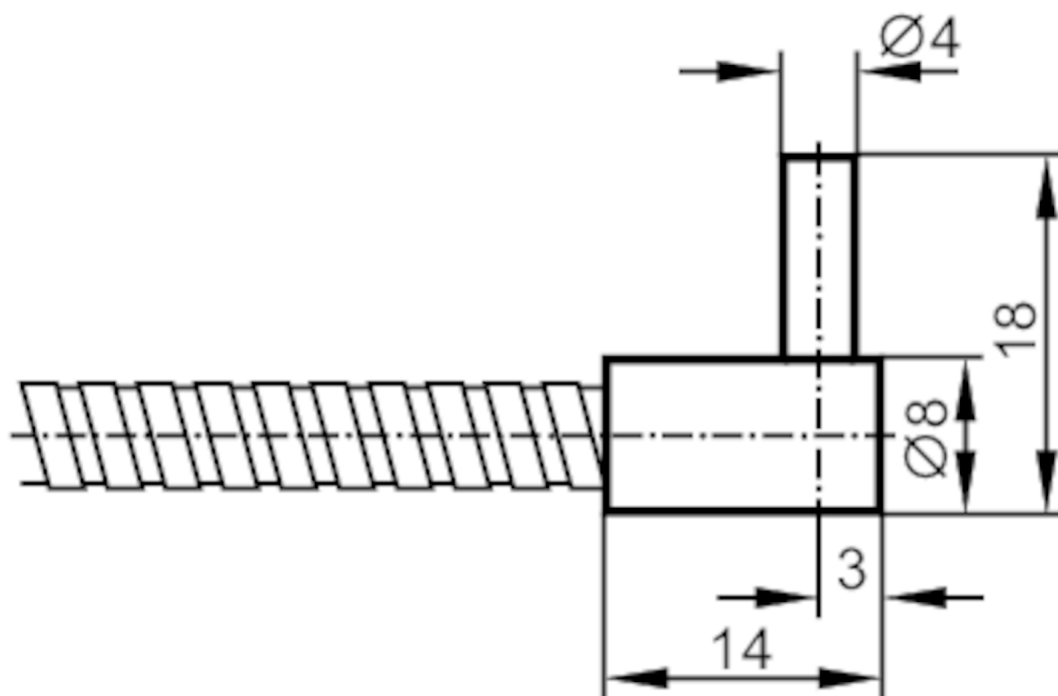

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic
amplifier type

OKF; OUF

OKF

Range fibre optics

[mm]

40

OUF

Range fibre optics

[mm]

40

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

angled

Sensing head diameter

[mm]

4

Sensing head length

[mm]

10

Total length

[mm]

220; (-10 %)

Min. bending radius

[mm]

20

Materials

Adapter: ABS

Fibre material

glass

E20521



Fibre optic diffuse reflection sensor

FT-00-A-A-R4/0,22M +/-10MM

Fibre head material	aluminium
Fibre sheath material	aluminium
Remarks	
Pack quantity	1 pcs.