




Fibre optic through-beam sensor

FE-00-M-V-E3/1,5m

Article no longer available - archive entry

Alternative articles: E20492
When selecting an alternative article and accessories please note that technical data may differ!

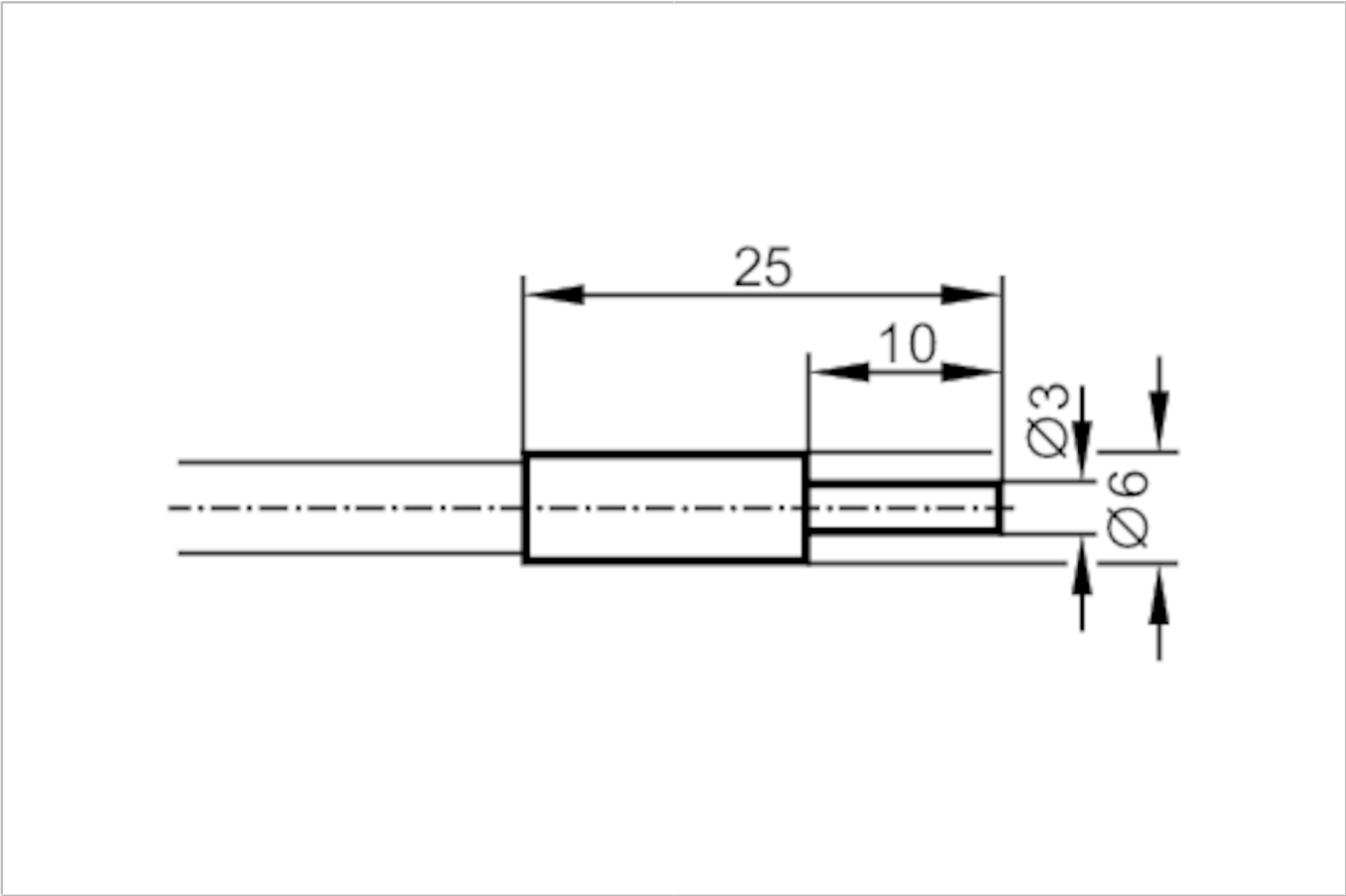

Application	
Function principle	Through-beam sensor
Detection zone	
Range with fibre-optic amplifier type	OKF; OUF
OKF	
Range of fibre optics [mm]	108
OUF	
Range of fibre optics [mm]	108
Operating conditions	
Ambient temperature [°C]	-20...150
Mechanical data	
Version of sensing head	straight
Sensing head diameter [mm]	3
Sensing head length [mm]	10
Total length [mm]	1500

E20536



Fibre optic through-beam sensor

FE-00-M-V-E3/1,5m

Min. bending radius	[mm]	20
Fibre material		glass
Fibre head material		stainless steel (303/1.4305)
Fibre sheath material		metal silicone
Remarks		
Pack quantity		1 pcs.