




## Fibre optic through-beam sensor

FE-00-M-V-R3/1,5m

Article no longer available - archive entry

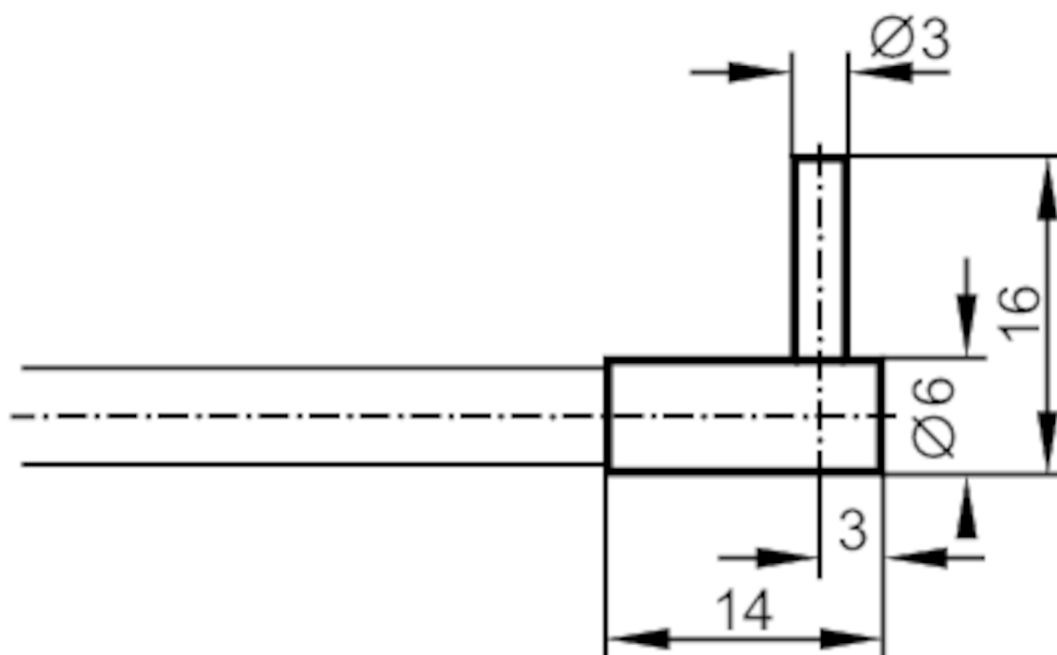

## Application

Function principle

Through-beam sensor

## Detection zone

Range with fibre-optic  
amplifier type

OKF; OUF

## OKF

Range of fibre optics

[mm]

108

## OUF

Range of fibre optics

[mm]

108

## Operating conditions

Ambient temperature

[°C]

-20...150

## Mechanical data

Version of sensing head

angled

Sensing head diameter

[mm]

3

Sensing head length

[mm]

10

Total length

[mm]

1500

Min. bending radius

[mm]

20

Fibre material

glass

Fibre head material

stainless steel (303/1.4305)

E20540



Fibre optic through-beam sensor

FE-00-M-V-R3/1,5m

|                       |                |
|-----------------------|----------------|
| Fibre sheath material | metal silicone |
| Remarks               |                |
| Pack quantity         | 1 pcs.         |