


Fibre optic diffuse reflection sensor

FT-00-P-A-R4/0,14M

Article no longer available - archive entry

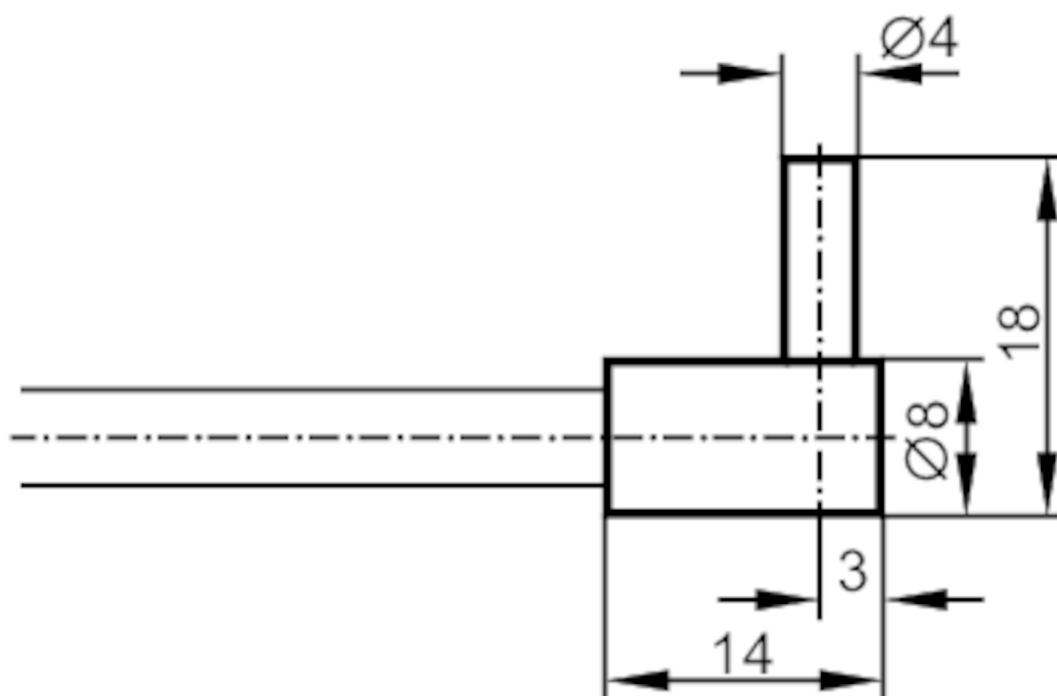

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic amplifier type

OKF; OUF

OKF

Range fibre optics

[mm]

40

OUF

Range fibre optics

[mm]

40

Operating conditions

Ambient temperature

[°C]

-20...150

Mechanical data

Version of sensing head

angled

Sensing head diameter

[mm]

4

Sensing head length

[mm]

10

Total length

[mm]

100; (+10 mm)

Min. bending radius

[mm]

20

Fibre material

glass

Fibre head material

stainless steel (303/1.4305)

E20566



Fibre optic diffuse reflection sensor

FT-00-P-A-R4/0,14M

Fibre sheath material	metal silicone
Remarks	
Pack quantity	1 pcs.