




Fibre optic diffuse reflection sensor

FT-00-P-A-R4/0,156 +/-6MM

Article no longer available - archive entry

Alternative articles: E20412
When selecting an alternative article and accessories please note that technical data may differ!

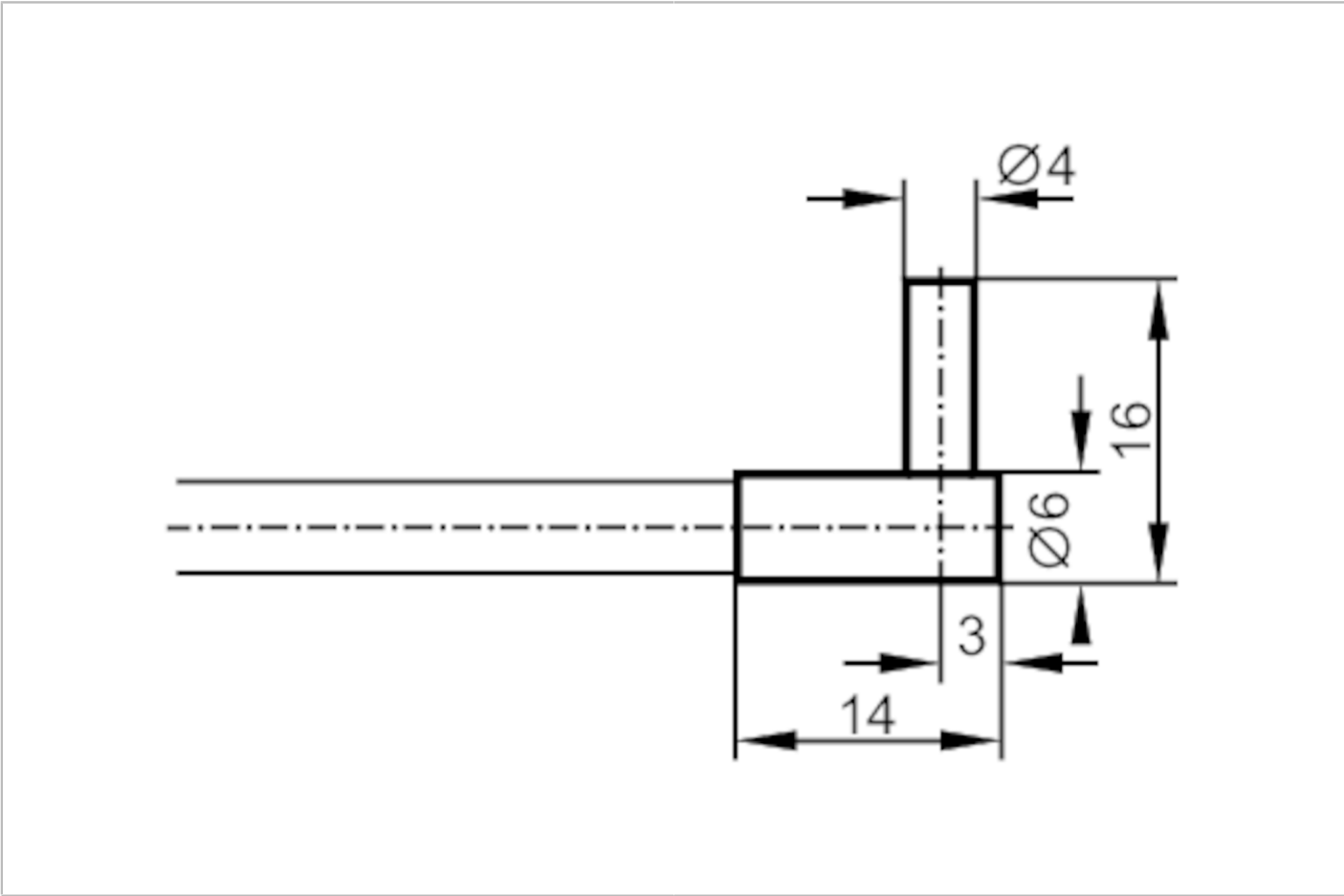

Application	
Function principle	Diffuse reflection sensor
Detection zone	
Range with fibre optic amplifier type	OKF; OUF
OKF	
Range fibre optics [mm]	40
OUF	
Range fibre optics [mm]	40
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Version of sensing head	angled
Sensing head diameter [mm]	4
Sensing head length [mm]	10
Total length [mm]	156; (-6 mm)

E20569



Fibre optic diffuse reflection sensor

FT-00-P-A-R4/0,156 +/-6MM

Min. bending radius	[mm]	20
Materials		Adapter: PPE
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		PVC
Аксессуары		
Items supplied		E20103
Remarks		
Pack quantity		1 pcs.