


Fibre optic through-beam sensor

FE-30-P-A-R6/1,2M

Article no longer available - archive entry

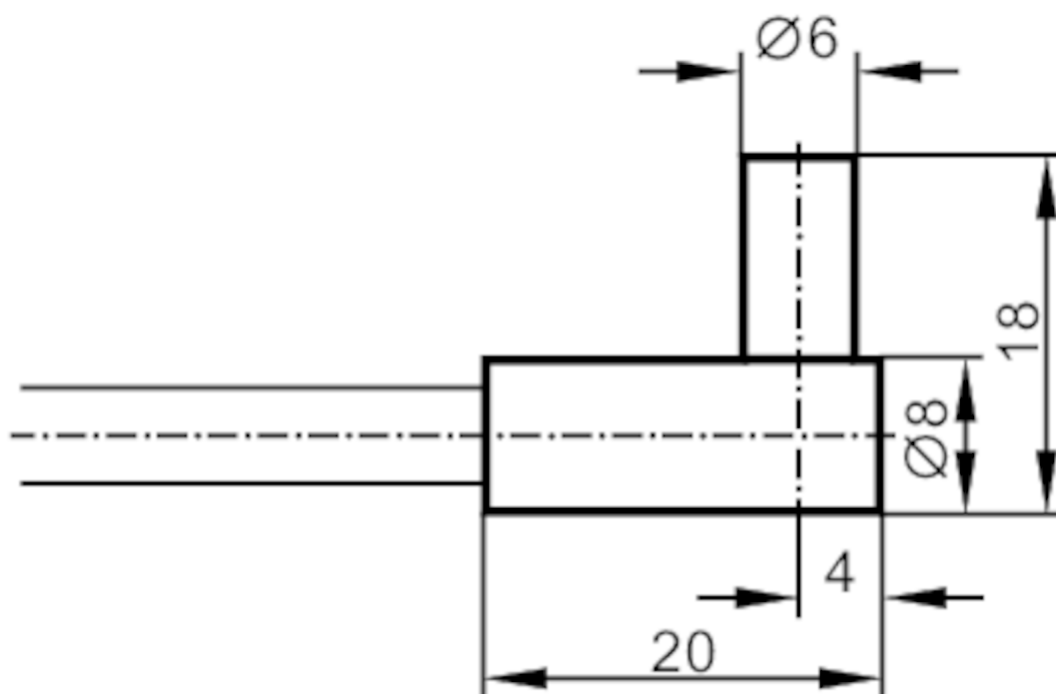

Application

Function principle

Through-beam sensor

Detection zone

Range with fibre-optic amplifier type

OIF

OIF

Range of fibre optics

[mm]

288

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Version of sensing head

angled

Total length

[mm]

1200

Min. bending radius

[mm]

30

Materials

Adapter: PA

Fibre material

glass

Fibre head material

aluminium

Fibre sheath material

PVC

Аксессуары

Items supplied

Mounting clamp:, E10221

E20581



Fibre optic through-beam sensor

FE-30-P-A-R6/1,2M

Remarks	
Pack quantity	1 pcs.