




Fibre optic diffuse reflection sensor

FT-18-A-A-M6/1M

Article no longer available - archive entry

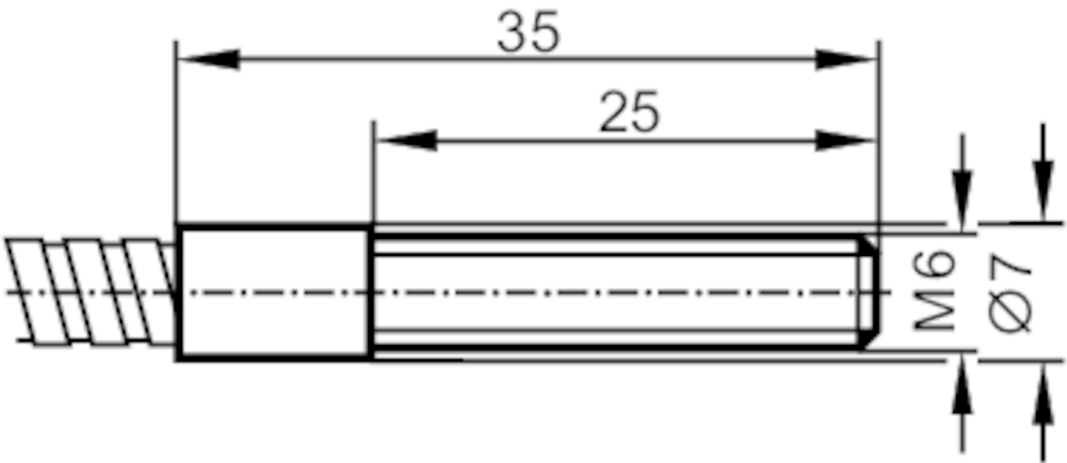

Application	
Function principle	Diffuse reflection sensor
Detection zone	
Range with fibre optic amplifier type	OGF
OGF	
Range fibre optics [mm]	15
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Version of sensing head	straight
Sensing head thread	M6
Sensing head length [mm]	25
Total length [mm]	1000
Min. bending radius [mm]	20
Materials	Adapter: PPE
Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	PVC

E20742



Fibre optic diffuse reflection sensor

FT-18-A-A-M6/1M

Remarks	
Pack quantity	1 pcs.